

Basic terminal block - PI-EX-TB - 2835901

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Ex base terminal block for intrinsically safe signals with knife disconnection and test connections



Key commercial data

package_quantity	10
GTIN	4017918911799

Technical data

Dimensions

Width	12.4 mm
Height	145 mm
Depth	86.5 mm

Ambient conditions

Ambient temperature (operation)	-20 °C ... 60 °C
Ambient temperature (storage/transport)	-40 °C ... 85 °C

General

Nominal voltage U_N	250 V
Nominal current I_N	4 A
Housing insulation material	PBT
Inflammability class according to UL 94	V0
Color	gray
Conformance	CE-compliant
ATEX	# II (1) G [Ex ia] IIC
ATEX	# II (1) D [Ex iaD]
ATEX	# II 3 G Ex nA II T4 X
UL, USA / Canada	Class I, Div. 2, Groups A, B, C, D

Connection data

Connection method	Screw connection
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	2.5 mm ²

Basic terminal block - PI-EX-TB - 2835901

Technical data

Connection data

Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	14
Screw thread	M3
Stripping length	12 mm
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	2.5 mm ²
Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	14
Screw thread	M3
Stripping length	12 mm
Tightening torque, min	0.5 Nm
Tightening torque max	0.6 Nm

classifications

eCl@ss

eCl@ss 4.0	27141127
eCl@ss 4.1	27141127
eCl@ss 5.0	27371603
eCl@ss 5.1	27371603
eCl@ss 6.0	27371603
eCl@ss 7.0	27371603
eCl@ss 8.0	27371603

ETIM

ETIM 2.0	EC000764
ETIM 3.0	EC001456
ETIM 4.0	EC001456
ETIM 5.0	EC001456

UNSPSC

UNSPSC 6.01	30211811
UNSPSC 7.0901	39121410
UNSPSC 11	39121410
UNSPSC 12.01	39121410
UNSPSC 13.2	39121410

Basic terminal block - PI-EX-TB - 2835901

approvals

ATEX / GOST /

Approval details

ATEX	
Nominal voltage UN	
Nominal current IN	
mm ² /AWG/kcmil	4

GOST	
------	--

accessories

Insulating sleeve

MPS-IH RD - 0201676



MPS-IH BU - 0201689



MPS-IH GY - 0201728



Basic terminal block - PI-EX-TB - 2835901

accessories

Screwdriver tools

SZG 0,6X3,5 VDE - 1205121



Terminal marking

ZBFM 6/WH:UNBEDRUCKT - 0803618



Labeled terminal marker

ZBFM 6/WH,LGS:1-100 - 0800284



ZBFM 6/WH,LGS:FORTL.ZAHLEN - 0803621



Bridge

FBST 500-PLC RD - 2966786



Basic terminal block - PI-EX-TB - 2835901

accessories

FBST 500-PLC BU - 2966692



FBST 500-PLC GY - 2966838



accessories

ZBFM 6:SO/CMS - 0803650




PI-ATP - 2835969



Drawings

Basic terminal block - PI-EX-TB - 2835901

Dimensioned drawing

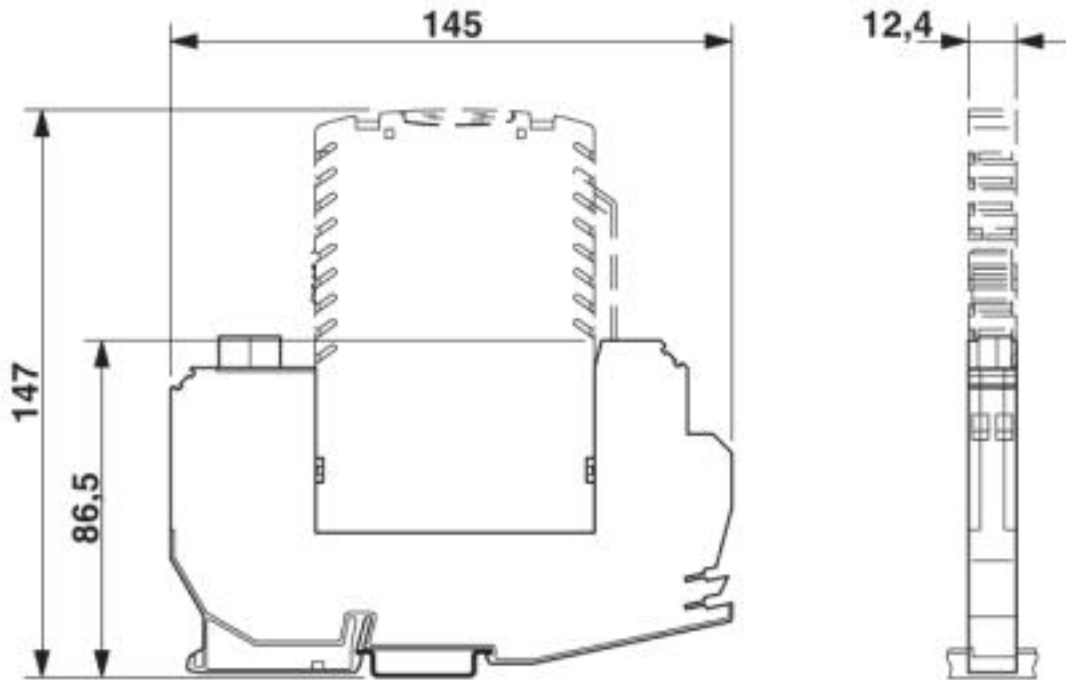

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>