

Interface module - VIP-2/SC/FLK16 - 2315036

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



VARIOFACE module, with screw connection and flat-ribbon cable connector, for mounting on NS 35 rails, with pin strip and short and long locking latches for socket strips, 16-pos.

The illustration shows a 14-position version

Product Features

- 10 to 64-pos.
- Metal foot
- According to IEC 60603-13
- Screw connection
- 1:1 connection



Key commercial data

package_quantity	1
GTIN	4046356312066

Technical data

Dimensions

Width	45 mm
Height	65.5 mm
Depth	56 mm

Ambient conditions

Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C

General

Nominal voltage U_N	60 V AC/DC
Max. current carrying capacity per branch	1 A
Number of positions	16
Status display	No
Mounting position	Any
Standards/regulations	IEC 60664
Standards/regulations	DIN EN 50178

Interface module - VIP-2/SC/FLK16 - 2315036

Technical data

General

Standards/regulations	IEC 62103
Pollution degree	2
Surge voltage category	II
Rated surge voltage	0.6 kV

Connection data for connection 1

Connection name	PCB connection
Connection in acc. with standard	IEC / EN
Connection method	Screw connection
Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	4 mm ²
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	12
Stripping length	8 mm
Screw thread	M 3

Connection data for connection 2

Connection name	Control system level
Number of connections	1
Connection method	IDC/FLK pin strip (2.54 mm)
Number of positions	16

classifications

eCl@ss

eCl@ss 4.0	27250313
eCl@ss 4.1	27250313
eCl@ss 5.0	27250313
eCl@ss 5.1	27250313
eCl@ss 6.0	27242608
eCl@ss 7.0	27242608
eCl@ss 8.0	27242608

ETIM

ETIM 2.0	EC001434
ETIM 3.0	EC001604
ETIM 4.0	EC001604
ETIM 5.0	EC001604

UNSPSC

UNSPSC 6.01	30211824
UNSPSC 7.0901	39121421

Interface module - VIP-2/SC/FLK16 - 2315036

classifications


UNSPSC


UNSPSC 11	39121421
UNSPSC 12.01	39121421
UNSPSC 13.2	39121421


approvals


CSA / UL Recognized / cUL Recognized / UL Recognized / cULus Recognized /

Approval details

CSA 	
Nominal voltage UN	125 V
Nominal current IN	1 A
mm ² /AWG/kcmil	30-12


UL Recognized 	
Nominal voltage UN	125 V
Nominal current IN	1 A
mm ² /AWG/kcmil	30-12

cUL Recognized 	
Nominal voltage UN	125 V
Nominal current IN	1 A
mm ² /AWG/kcmil	30-12

	
Nominal voltage UN	125 V
Nominal current IN	1 A
mm ² /AWG/kcmil	30-12

Interface module - VIP-2/SC/FLK16 - 2315036

approvals

cULus Recognized  US

accessories

System cable

VIP-CAB-FLK16/0,14/0,5M - 2318460



VIP-CAB-FLK16/0,14/1,0M - 2318473



VIP-CAB-FLK16/0,14/1,5M - 2318486



VIP-CAB-FLK16/0,14/2,0M - 2318499



VIP-CAB-FLK16/0,14/3,0M - 2318509



Interface module - VIP-2/SC/FLK16 - 2315036

accessories

VIP-CAB-FLK16/0,14/4,0M - 2318512



VIP-CAB-FLK16/0,14/6,0M - 2318525



VIP-CAB-FLK16-0,14/... - 2318538



FLK 16/EZ-DR/ 50/KONFEK - 2299291



FLK 16/EZ-DR/ 100/KONFEK - 2299301



Interface module - VIP-2/SC/FLK16 - 2315036

accessories

FLK 16/EZ-DR/ 150/KONFEK - 2299314



FLK 16/EZ-DR/ 200/KONFEK - 2299327



FLK 16/EZ-DR/ 300/KONFEK - 2299330



FLK 16/EZ-DR/ 400/KONFEK - 2299343



FLK 16/EZ-DR/ 600/KONFEK - 2299356



FLK 16/EZ-DR/ 800/KONFEK - 2299369



Interface module - VIP-2/SC/FLK16 - 2315036

accessories

FLK 16/EZ-DR/1000/KONFEK - 2299372



FLK EZ-DR.../.../... - 2295059



FLK 16/EZ-DR/ 100/KONFEK/S - 2304542



FLK 16/EZ-DR/ 150/KONFEK/S - 2304623



FLK 16/EZ-DR/ 200/KONFEK/S - 2304555



Interface module - VIP-2/SC/FLK16 - 2315036

accessories

FLK 16/EZ-DR/ 300/KONFEK/S - 2318088



FLK 16/EZ-DR/ 400/KONFEK/S - 2318091



FLK 16/EZ-DR/ 500/KONFEK/S - 2318965



FLK 16/EZ-DR/ 600/KONFEK/S - 2314477



FLK EZ-DR-S.../.../... - 2295046



Terminal marking

Interface module - VIP-2/SC/FLK16 - 2315036

accessories

UC-TM 4 - 0818111



UC-TM 6 - 0818085



ZB 5,08:UNBEDRUCKT - 0809793



ZB 22:UNBEDRUCKT - 0811862



accessories


BLUEMARK X1 - 5147777



Drawings

Interface module - VIP-2/SC/FLK16 - 2315036

Circuit diagram

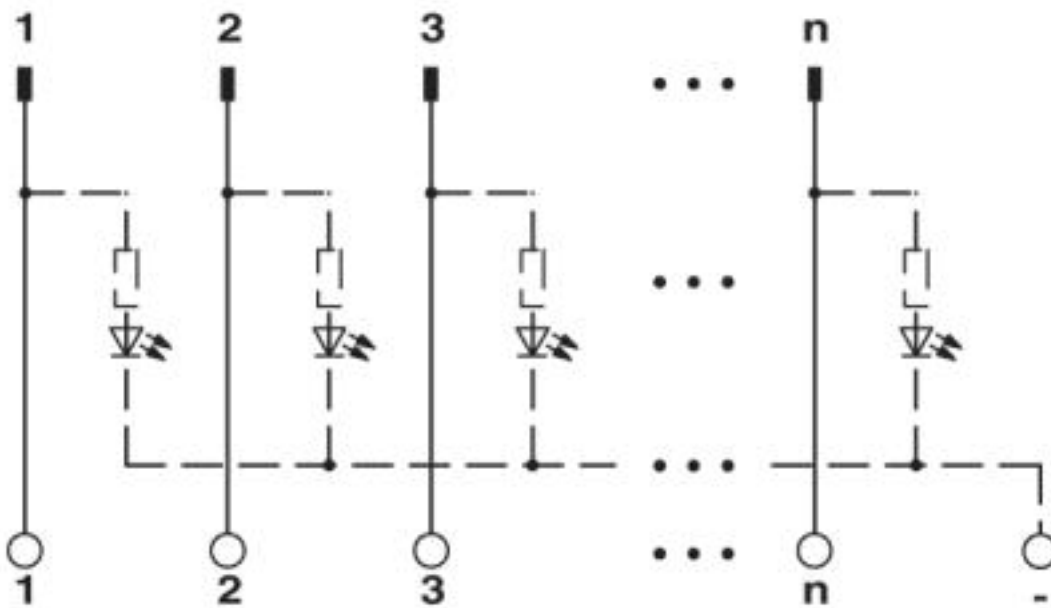

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>