

Interface module - UM 45-D50SUB/B/ZFKDS - 2293705

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



VARIOFACE module, with spring-cage connection and D-Subminiature socket strip, for mounting on NS 35/7.5, 50-pos.

The illustration shows version UM 45-D 37SUB/S/ZFKDS

Product Features

- 9 to 50-pos.
- Spring-cage connection technology
- According to IEC 60807-2
- 1:1 connection



Key commercial data

package_quantity	1
GTIN	4017918120603

Technical data

Dimensions

Width	156 mm
Height	45 mm
Depth	50 mm

Ambient conditions

Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C

General

Nominal voltage U_N	125 V AC/DC
Max. current carrying capacity per branch	2.5 A
Max. current carrying capacity per branch	1.5 A (with even load on all branches)
Number of positions	50
Status display	No
Test voltage	800 V (50 Hz, 1 min.)
Mounting position	Any
Standards/regulations	IEC 60664

Interface module - UM 45-D50SUB/B/ZFKDS - 2293705

Technical data

General

Standards/regulations	DIN EN 50178
Standards/regulations	IEC 62103
Pollution degree	2
Surge voltage category	II
Rated surge voltage	1.2 kV
Rated insulation voltage	125 V

Connection data for connection 1

Connection name	PCB connection
Connection in acc. with standard	IEC / EN
Connection method	Spring-cage connection
Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	2.5 mm ²
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	1.5 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	14
Stripping length	8 mm
Screw thread	M3

Connection data for connection 2

Connection name	D-SUB connection
Number of connections	1
Connection method	D-SUB socket strip
Number of positions	50

classifications

eCl@ss

eCl@ss 4.0	27250313
eCl@ss 4.1	27250313
eCl@ss 5.0	27250313
eCl@ss 5.1	27250313
eCl@ss 6.0	27242608
eCl@ss 7.0	27141152
eCl@ss 8.0	27141152

ETIM

ETIM 2.0	EC001434
ETIM 3.0	EC001604
ETIM 4.0	EC001604
ETIM 5.0	EC002780

UNSPSC

Interface module - UM 45-D50SUB/B/ZFKDS - 2293705

classifications


UNSPSC

UNSPSC 6.01	30211824
UNSPSC 7.0901	39121421
UNSPSC 11	39121421
UNSPSC 12.01	39121421
UNSPSC 13.2	39121421

approvals

GOST /

 Approval details



accessories

Screwdriver tools

SZF 0-0,4X2,5 - 1204504



System cable

CABLE-D50SUB/B/S/ 50/KONFEK/S - 2302269



CABLE-D50SUB/B/S/100/KONFEK/S - 2302272



Interface module - UM 45-D50SUB/B/ZFKDS - 2293705

accessories

CABLE-D50SUB/B/S/150/KONFEK/S - 2302285



CABLE-D50SUB/B/S/200/KONFEK/S - 2302298



CABLE-D50SUB/B/S/300/KONFEK/S - 2302308



CABLE-D50SUB/B/S/400/KONFEK/S - 2302311



CABLE-D50SUB/B/S/600/KONFEK/S - 2302324



Interface module - UM 45-D50SUB/B/ZFKDS - 2293705

accessories

CABLE D-SUB-S/.../.../... - 2302340



CABLE D-SUB-S-S/.../.../... - 2302434



CABLE-D-50SUB/M/OE/0,25/S/0,5M - 2926645



CABLE-D-50SUB/M/OE/0,25/S/1,0M - 2926658



CABLE-D-50SUB/M/OE/0,25/S/1,5M - 2926661



CABLE-D-50SUB/M/OE/0,25/S/2,0M - 2926674



Interface module - UM 45-D50SUB/B/ZFKDS - 2293705

accessories

CABLE-D-50SUB/M/OE/0,25/S/3,0M - 2926687



CABLE-D-50SUB/M/OE/0,25/S/4,0M - 2926690



CABLE-D-50SUB/M/OE/0,25/S/6,0M - 2926700




CABLE-D-50SUB-M-OE-0,25-S/... - 2900913



Drawings

Interface module - UM 45-D50SUB/B/ZFKDS - 2293705

Circuit diagram

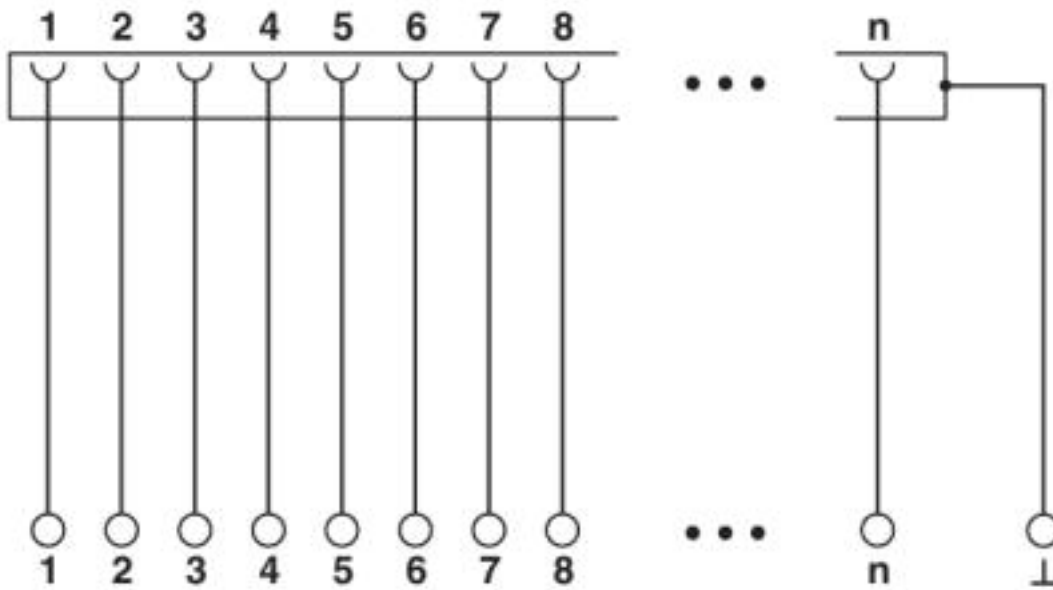

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>