

## Cable gland - VC-K-KV-PG21-1X8,5/1X12 - 1885279

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Half screw connection Pg21, made of plastic, consisting of rubber seal with several holes (1 x 8.5 mm/1 x 12 mm) and a pressure screw, for cable screw connection thread VC-M-KV-PG21.....

### Key commercial data

package_quantity	5
GTIN	4017918176389

### Technical data

#### Dimensions

Wrench size, union nut	33 mm
External cable diameter	8 mm ... 8.5 mm (Cable 1)
External cable diameter	11.5 mm ... 12 mm (Cable 2)

#### Ambient conditions

Degree of protection	IP67
Degree of protection	IP67
Ambient temperature (operation)	-20 °C ... 100 °C

#### General

Type of the screw connection	Half screw connection
Material, pressure screw	Polyamide
Seal material	TPE
Thread type on seal side	Pg21
Tightening torque, union nut	7.50 Nm

### classifications

#### eCl@ss

eCl@ss 4.0	27141209
eCl@ss 4.1	27141209
eCl@ss 5.0	27149109
eCl@ss 5.1	27149109
eCl@ss 6.0	27149109
eCl@ss 7.0	27149109
eCl@ss 8.0	27149109

# Cable gland - VC-K-KV-PG21-1X8,5/1X12 - 1885279

## classifications

### ETIM

ETIM 2.0	EC000441
ETIM 3.0	EC000441
ETIM 4.0	EC000441
ETIM 5.0	EC000441

### UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261502

 
## approvals

---

GOST /

---

### Approval details



## accessories

### Half screw connection


VC-K-KV-PG21-O - 1885363

---

## Drawings

# Cable gland - VC-K-KV-PG21-1X8,5/1X12 - 1885279

Dimensioned drawing

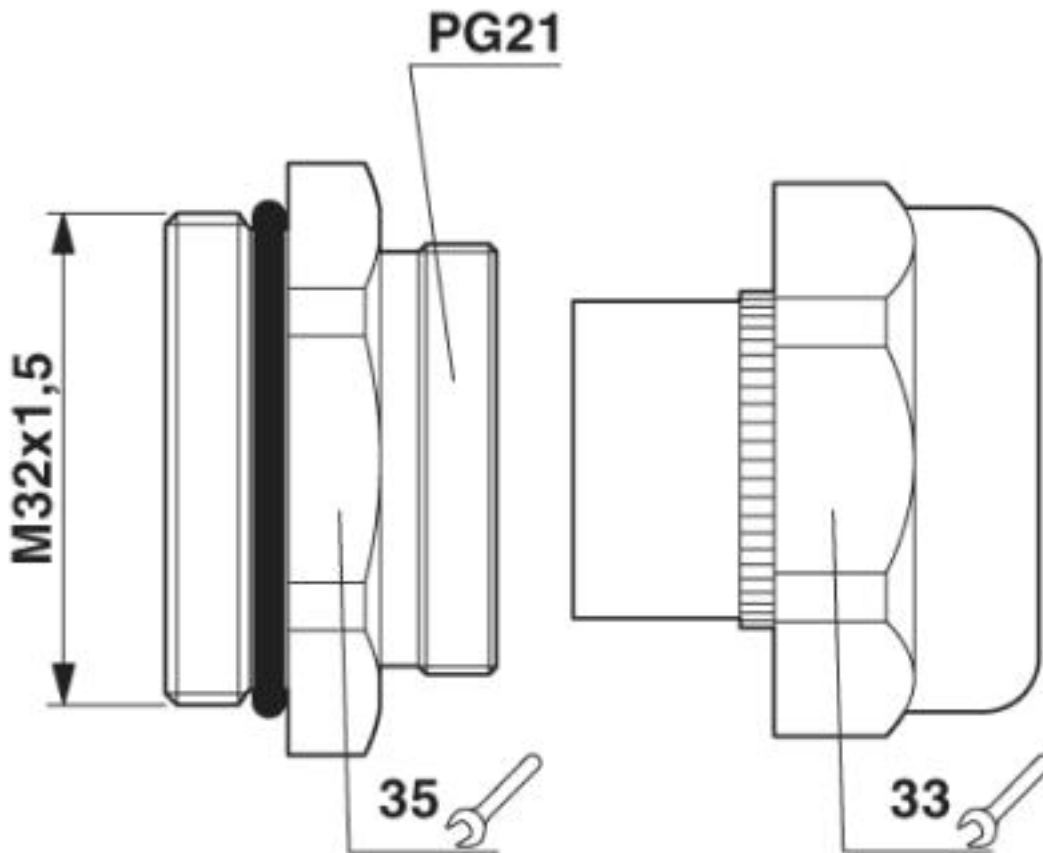

© Phoenix Contact 2013 - all rights reserved  
<http://www.phoenixcontact.com>