

System connectors - FLKM 50-PA-S400(3-48) - 2294908

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



VARIOFACE front adapter, for Siemens SIMATIC® S7-400, only analog

The illustration shows version
FLKM 50-PA-S400

Product Features

- Analog channels are connected via a 50-pos. system cable

Key commercial data

package_quantity	2
GTIN	4017918156350

Technical data

General

Nominal voltage U_N	< 50 V AC
Nominal voltage U_N	60 V DC
Max. permissible current	1 A (per path)
Channels which can be connected	32
Connection type, connector	IDC/FLK pin strip (2.54 mm)
Number of connectors	1
No. of positions, connector	50
Number of positions	50
Mounting position	Any
Standards/regulations	IEC 60664
Standards/regulations	DIN EN 50178
Standards/regulations	IEC 62103
Pollution degree	2
Surge voltage category	II

Ambient conditions

Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C

Supported controller

Control	SIEMENS S7-400
- suitable I/O card	6ES7 431-0HH0-0AB0

System connectors - FLKM 50-PA-S400(3-48) - 2294908

Technical data

Supported controller

- suitable I/O card	6ES7 431-1KF00-0AB0
- suitable I/O card	6ES7 431-1KF10-0AB0
- suitable I/O card	6ES7 431-1KF20-0AB0
- suitable I/O card	6ES7 431-7KF00-0AB0
- suitable I/O card	6ES7 431-7KF10-0AB0
- suitable I/O card	6ES7 431-7QH00-0AB0
- suitable I/O card	6ES7 432-1HF00-0AB0

classifications

eCl@ss

eCl@ss 4.0	27250313
eCl@ss 4.1	27250313
eCl@ss 5.0	27250313
eCl@ss 5.1	27250313
eCl@ss 6.0	27242208
eCl@ss 7.0	27242208
eCl@ss 8.0	27242208

ETIM

ETIM 2.0	EC001423
ETIM 3.0	EC001423
ETIM 4.0	EC001423
ETIM 5.0	EC001423

UNSPSC

UNSPSC 6.01	30211824
UNSPSC 7.0901	39121421
UNSPSC 11	39121421
UNSPSC 12.01	39121421
UNSPSC 13.2	39121421

approvals

GOST /


Approval details



Drawings

System connectors - FLKM 50-PA-S400(3-48) - 2294908

Circuit diagram

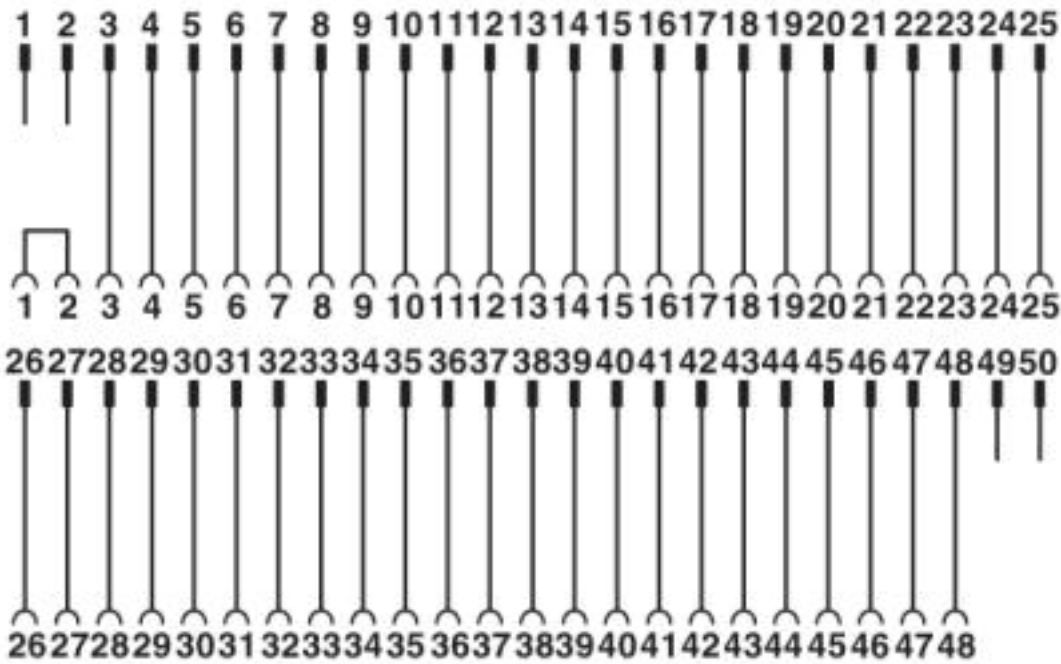

Connection scheme FLKM 50-PA-S400 (3-48)

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>