

Interface module - VIP-3/SC/FLK50 - 2315081

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



VARIOFACE module, with screw connection and flat-ribbon cable connector, for mounting on NS 35 rails, with pin strip and short and long locking latches for socket strips, 50-pos.

Product Features

- 10 to 64-pos.
- Metal foot
- According to IEC 60603-13
- Screw connection
- 1:1 connection



Key commercial data

package_quantity	1
GTIN	4046356312899

Technical data

Dimensions

Width	92.7 mm
Height	69 mm
Depth	62 mm

Ambient conditions

Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C

General

Nominal voltage U_N	60 V AC/DC
Max. current carrying capacity per branch	1 A
Number of positions	50
Status display	No
Mounting position	Any
Standards/regulations	IEC 60664
Standards/regulations	DIN EN 50178
Standards/regulations	IEC 62103

Interface module - VIP-3/SC/FLK50 - 2315081

Technical data

General

Pollution degree	2
Surge voltage category	II
Rated surge voltage	0.6 kV

Connection data for connection 1

Connection name	PCB connection
Connection in acc. with standard	IEC / EN
Connection method	Screw connection
Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	4 mm ²
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	12
Stripping length	8 mm
Screw thread	M 3

Connection data for connection 2

Connection name	Control system level
Number of connections	1
Connection method	IDC/FLK pin strip (2.54 mm)
Number of positions	50

classifications

eCl@ss

eCl@ss 4.0	27250313
eCl@ss 4.1	27250313
eCl@ss 5.0	27250313
eCl@ss 5.1	27250313
eCl@ss 6.0	27242608
eCl@ss 7.0	27242608
eCl@ss 8.0	27242608

ETIM

ETIM 2.0	EC001434
ETIM 3.0	EC001604
ETIM 4.0	EC001604
ETIM 5.0	EC001604

UNSPSC

UNSPSC 6.01	30211824
UNSPSC 7.0901	39121421
UNSPSC 11	39121421

Interface module - VIP-3/SC/FLK50 - 2315081

classifications

UNSPSC

UNSPSC 12.01	39121421
UNSPSC 13.2	39121421

approvals

CSA / UL Recognized / cUL Recognized / UL Recognized / cULus Recognized /

Approval details

CSA	
Nominal voltage UN	125 V
Nominal current IN	1 A
mm ² /AWG/kcmil	30-12

UL Recognized	
Nominal voltage UN	125 V
Nominal current IN	1 A
mm ² /AWG/kcmil	30-12

cUL Recognized	
Nominal voltage UN	125 V
Nominal current IN	1 A
mm ² /AWG/kcmil	30-12

Nominal voltage UN	125 V
Nominal current IN	1 A
mm ² /AWG/kcmil	30-12

Interface module - VIP-3/SC/FLK50 - 2315081

approvals

cULus Recognized 

accessories

System cable

VIP-CAB-FLK50/0,14/0,5M - 2318868



VIP-CAB-FLK50/0,14/1,0M - 2318871



VIP-CAB-FLK50/0,14/1,5M - 2318884



VIP-CAB-FLK50/0,14/2,0M - 2318897



VIP-CAB-FLK50/0,14/3,0M - 2318907



Interface module - VIP-3/SC/FLK50 - 2315081

accessories

VIP-CAB-FLK50/0,14/4,0M - 2318910



VIP-CAB-FLK50/0,14/6,0M - 2318923



VIP-CAB-FLK50-0,14/... - 2318936



FLK 50/EZ-DR/ 50/KONFEK - 2289065



FLK 50/EZ-DR/ 100/KONFEK - 2289078



Interface module - VIP-3/SC/FLK50 - 2315081

accessories

FLK 50/EZ-DR/ 150/KONFEK - 2289081



FLK 50/EZ-DR/ 200/KONFEK - 2289094



FLK 50/EZ-DR/ 250/KONFEK - 2289104



FLK 50/EZ-DR/ 300/KONFEK - 2289117



FLK 50/EZ-DR/ 350/KONFEK - 2289120



FLK 50/EZ-DR/ 400/KONFEK - 2289133



Interface module - VIP-3/SC/FLK50 - 2315081

accessories

FLK 50/EZ-DR/ 450/KONFEK - 2289573



FLK 50/EZ-DR/ 500/KONFEK - 2289586



FLK 50/EZ-DR/ 550/KONFEK - 2289599



FLK 50/EZ-DR/ 600/KONFEK - 2289609



FLK 50/EZ-DR/ 650/KONFEK - 2289612



Interface module - VIP-3/SC/FLK50 - 2315081

accessories

FLK 50/EZ-DR/ 700/KONFEK - 2289625



FLK 50/EZ-DR/ 750/KONFEK - 2289638



FLK 50/EZ-DR/ 800/KONFEK - 2289641



FLK 50/EZ-DR/ 850/KONFEK - 2289654



FLK 50/EZ-DR/ 900/KONFEK - 2289667



FLK 50/EZ-DR/ 950/KONFEK - 2289670



Interface module - VIP-3/SC/FLK50 - 2315081

accessories

FLK 50/EZ-DR/1000/KONFEK - 2289683



FLK EZ-DR.../.../... - 2295059



FLK 50/EZ-DR/ 50/KONFEK/S - 2299097



FLK 50/EZ-DR/ 100/KONFEK/S - 2299107



FLK 50/EZ-DR/ 150/KONFEK/S - 2299110



Interface module - VIP-3/SC/FLK50 - 2315081

accessories

FLK 50/EZ-DR/ 200/KONFEK/S - 2299123



FLK 50/EZ-DR/ 300/KONFEK/S - 2299136



FLK 50/EZ-DR/ 400/KONFEK/S - 2299149



FLK 50/EZ-DR/ 600/KONFEK/S - 2299152



FLK 50/EZ-DR/ 800/KONFEK/S - 2299165



FLK 50/EZ-DR/1000/KONFEK/S - 2299178



Interface module - VIP-3/SC/FLK50 - 2315081

accessories

FLK EZ-DR-S.../.../... - 2295046



CABLE-FLK50/0,14/HF/ 0,5M - 2314134



CABLE-FLK50/0,14/HF/ 1,0M - 2314147



CABLE-FLK50/0,14/HF/ 1,5M - 2314150



CABLE-FLK50/0,14/HF/ 2,0M - 2314163



Interface module - VIP-3/SC/FLK50 - 2315081

accessories

CABLE-FLK50/0,14/HF/ 2,5M - 2314176



CABLE-FLK50/0,14/HF/ 5,0M - 2314202



CABLE-FLK50/0,14/HF/ 6,0M - 2314215



CABLE-FLK50/0,14/HF/ 7,0M - 2314228



CABLE-FLK50/0,14/HF/ 8,0M - 2314231



CABLE-FLK50-0,14-HF/... - 2314257



Interface module - VIP-3/SC/FLK50 - 2315081

accessories

Terminal marking

UC-TM 4 - 0818111



UC-TM 6 - 0818085



ZB 5,08:UNBEDRUCKT - 0809793



ZB 22:UNBEDRUCKT - 0811862



accessories


BLUEMARK X1 - 5147777



Drawings

Interface module - VIP-3/SC/FLK50 - 2315081

Circuit diagram

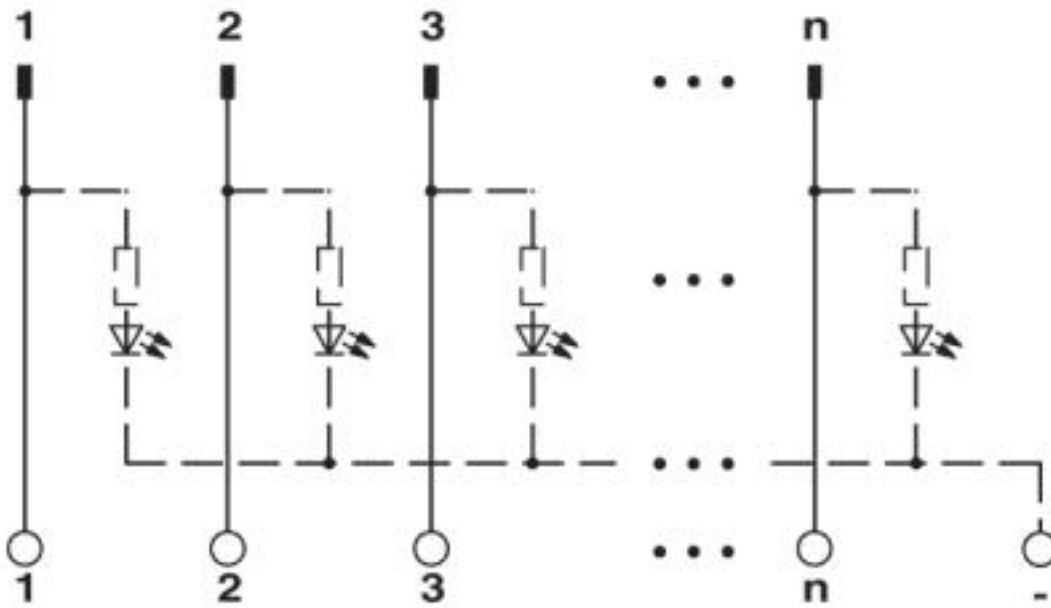

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>