

Contact - HC-D 4-2BU - 1886140

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Shield connection for two shielded cables on female contact carriers, without loose crimp contacts

Key commercial data

package_quantity	1
GTIN	4046356435345

Technical data

Ambient conditions

Ambient temperature (operation)	-40 °C ... 60 °C
---------------------------------	------------------

General

Note	For HC-D40-, HC-D64-, HC-M-12- contact carriers
------	---

classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27260704
eCl@ss 7.0	27440402
eCl@ss 8.0	27440402

ETIM

ETIM 3.0	EC000796
ETIM 4.0	EC002650
ETIM 5.0	EC002650

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

Contact - HC-D 4-2BU - 1886140

approvals

GOST /

Approval details



accessories

Assembly tool

CK1,6/2,5-MWZ - 1676734



VC-EW 1,6 - 1884869



Crimping tool


CRIMPFOX-1,6/2,5-ED-4,0 - 1687419



Drawings

Contact - HC-D 4-2BU - 1886140

Dimensioned drawing

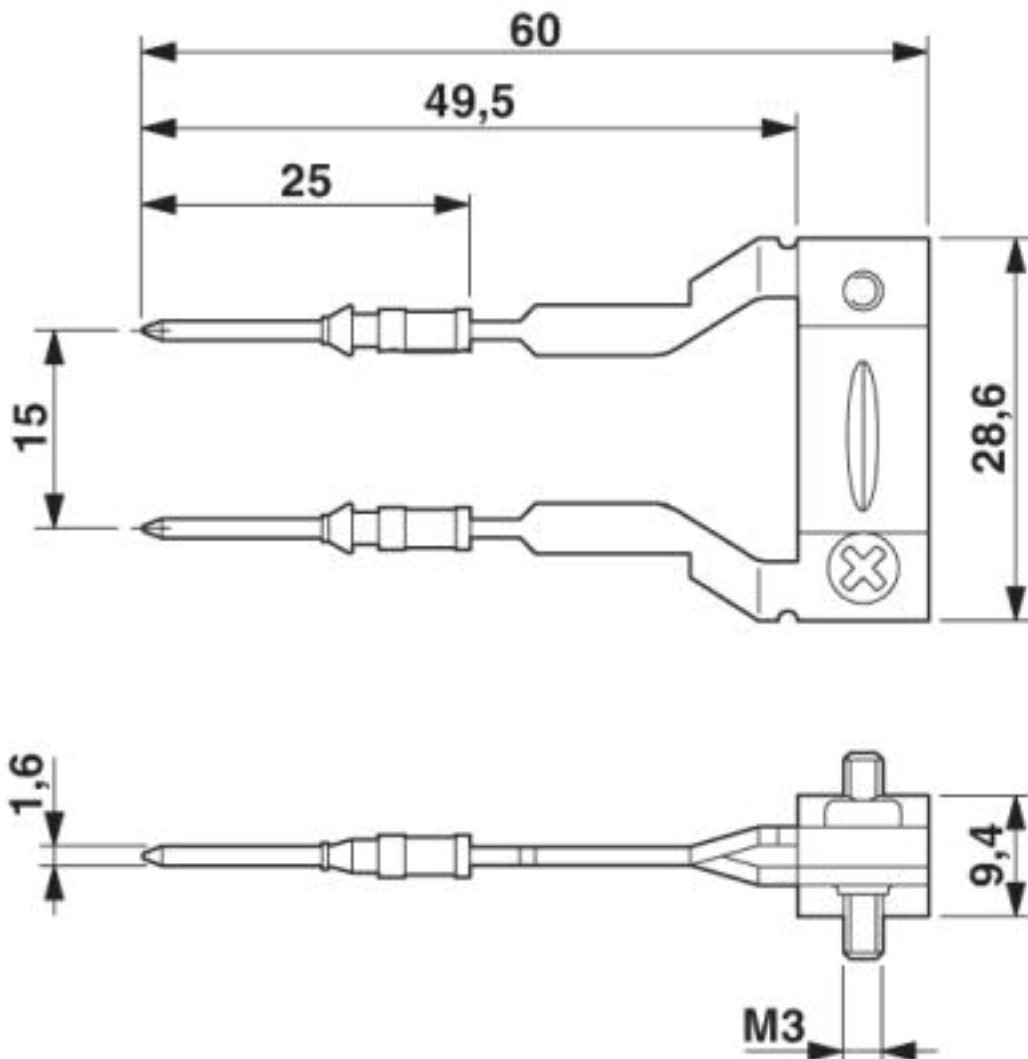

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>