

Front plate - VS-SI-FP-2DSUB9-GC-BU/ST - 1657708

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Front plate with contact inserts, plastic, 2x D-SUB 9, socket/pin

Illustration shows the product version VS-SI-FP-2RJ45-5-MOD-BU/BU

Key commercial data

package_quantity	1
GTIN	4046356118347

Technical data

Mechanical characteristics

Number of slots	2
Color	gray

Ambient conditions

Ambient temperature (operation)	-10 °C ... 60 °C
Degree of protection	IP20

Material data

Inflammability class according to UL 94	V0
Housing material	PBT

Electrical characteristics

Rated voltage (III/3)	125 V
Rated current	3 A

classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27189239
eCl@ss 5.1	27189239
eCl@ss 6.0	27144001
eCl@ss 7.0	27144001
eCl@ss 8.0	27144001

Front plate - VS-SI-FP-2DSUB9-GC-BU/ST - 1657708

classifications

ETIM

ETIM 2.0	EC000007
ETIM 3.0	EC000007
ETIM 4.0	EC000007
ETIM 5.0	EC000456


UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

approvals

GOST /

 Approval details



accessories

Marking material


VS-SI-BZ - 1656660



Drawings

Front plate - VS-SI-FP-2DSUB9-GC-BU/ST - 1657708

Dimensioned drawing

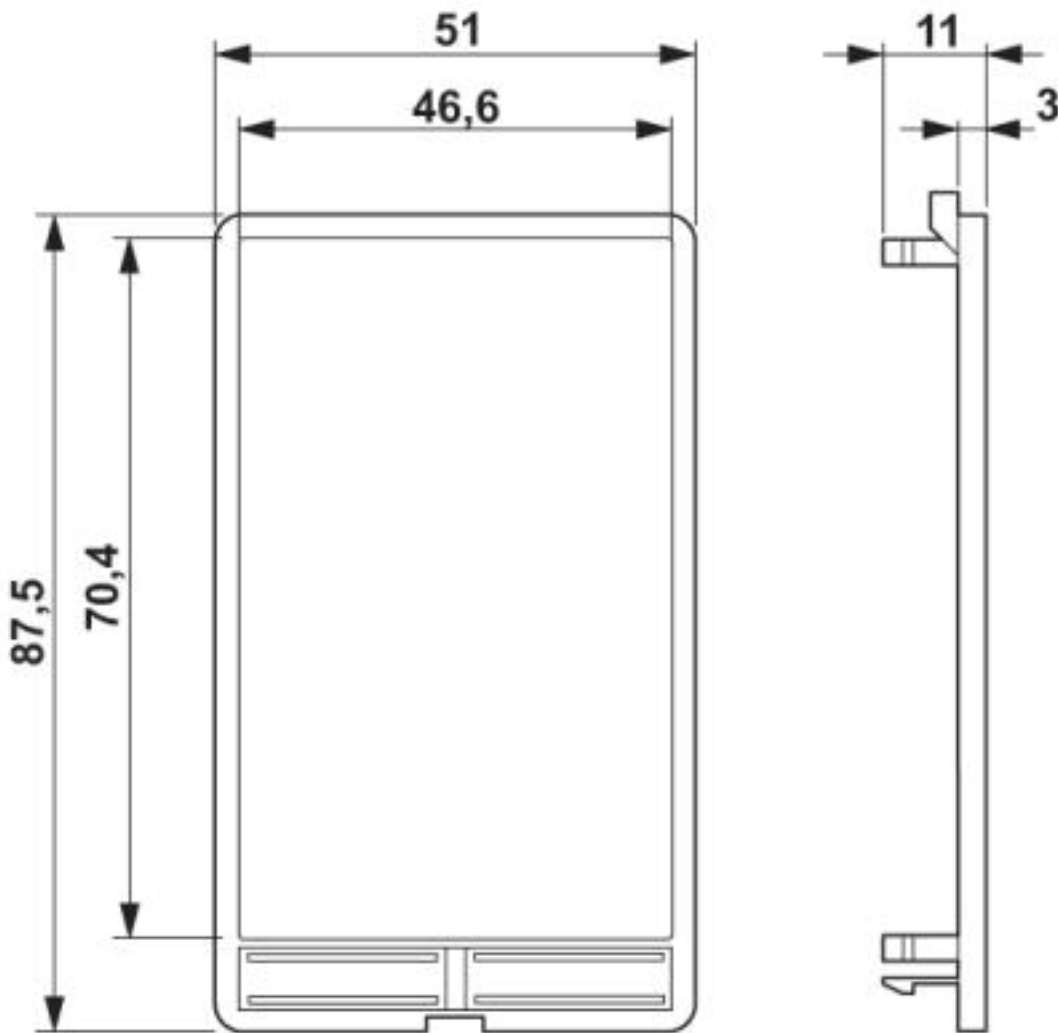

Front plate

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>