

LogiLink®




PC Case Cooler 80 x 80 x 25mm

Art. No.: FAN101
FAN102

The optimum cooling solution for your computer!

Specification:

Bearing Type	Sleeve bearing
Rated Voltage	DC 12V
Rated Current	0.14A±10% (FAN101)/0.17A±10% (FAN102)
Rated Power	1.68W (FAN101)/2.04W (FAN102)
Rated Speed (RPM)	2500±10% RPM
Airflow	22.4 CFM
Noise Level	19.16dB(A)
Lifespan	25000 hours
Dimension	80 x 80 x 25mm
Weight	68g (FAN101)/70g (FAN102)
Connector Type	4-pin
Environment	Operating Temperature: -10°C~70°C Storage Temperature: -40~70°C

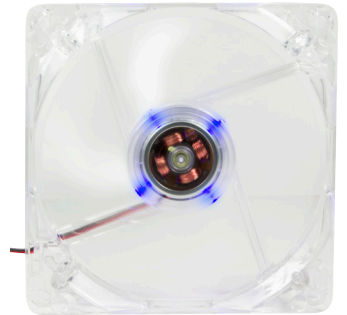

Art-No.	Product Overview	EAN Code
FAN101	Black	4260113565254
FAN102	Acryl with 4 LEDs	4260113565261

Package Content:

» 1 x PC Case Cooler

Package Information:

Art-No.	Packing Dimension	Packing Weight	Carton Dimension	Carton Q'ty	Carton Weight
FAN101	80 x 80 x 25mm	0.065kg	440 x 270 x 370mm	200pcs	13kg
FAN102	80 x 80 x 25mm	0.055kg	440 x 270 x 370mm	200pcs	12kg



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

Made in China

Best Connectivity