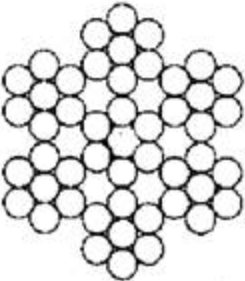


# EN 12385-4 Tabelle 5 – Seilkonstruktion 6x7+WSC

rope construction according to EN 12385-4 Table 5 – 6x7+WC

Querschnitt <i>cross section</i>	Artikelnummer <i>code number</i>	Durchmesser max.Toleranzen <i>diameter max. tol. in %</i>		Gewicht kg/m nur zur Information <i>approx. weight/mtr.</i>	Mindestbruchkraft 1770N/mm <sup>2</sup> <i>minimum breaking load</i>
		mm		kg	kN
	132 111 00150	1,5	+8%	0,0088	1,43
	132 111 00200	2	+8%	0,0154	2,54
	132 111 00300	3	+8%	0,0346	5,72
	132 111 00400	4	+7%	0,0614	10,2
	132 111 00500	5	+7%	0,0960	15,9
	132 111 00600	6	+6%	0,138	22,9
	132 111 00700	7	+6%	0,188	31,1
	132 111 00800	8	+5%	0,246	40,7
	132 111 00900	9	+5%	0,311	51,5
	132 111 01000	10	+5%	0,384	63,5
	132 111 01100	11	+5%	0,465	76,9
	132 111 01200	12	+5%	0,553	91,5