

DIGITUS® CAT 3 ISDN Patch Panel



✓ For 483 mm (19") rack mount

✓ Category 3

✓ Unshielded

✓ 25- or 50-port version

Abstract

DIGITUS® CAT 3 ISDN Patch Panel, unshielded, rack mount, 1U, color grey (RAL 7035), 25- or 50-port

Features

- Suitable for 483 mm (19") rack mount
- Material housing: SECC, 1.5 mm galvanized, cold-rolled Steel acc. EN1.4301
- Unshielded RJ45 jacks, 8P8C
- Contact material: Phosphor bronze
- Contacts coating: Nickel, gold-plated 0.3 μ
- Cable installation via LSA strips, color coded acc. EIA/TIA 568 A&B
- Material IDC Terminal: Phosphor bronze with 50 μ tin plated over 60 μ nickel plated
- Material PCB: FR4, UL 94V-0, multilayer 1.45 mm thickness
- Insertion force: ≤ 30 N
- Mating cycles: ≥ 750 (ISO/IEC 11801, IEC 60603-7-5)
- Operating temperature: -20 °C up to +70 °C
- Current carrying capacity: 1A at 50 °C
- Isolation resistance: > 500M Ω

Product Overview



The ISDN Patch Panels of Category 3 from DIGITUS® are available as 25- or 50-port version. With 1.5 mm galvanized cold-rolled steel they are perfectly suitable for 19" rack mounting.

Product Number Information

- | | |
|------------|--|
| DN-91325-1 | DIGITUS CAT 3 ISDN Patch Panel, unshielded, 25-port RJ45, 8P4C, LSA, 1U, rack mount, color grey (RAL 7035) |
| DN-91350-1 | DIGITUS CAT 3 ISDN Patch Panel, unshielded, 50-port RJ45, 8P4C, LSA, 1U, rack mount, color grey (RAL 7035) |

Technical Drawings

DN-91325-1

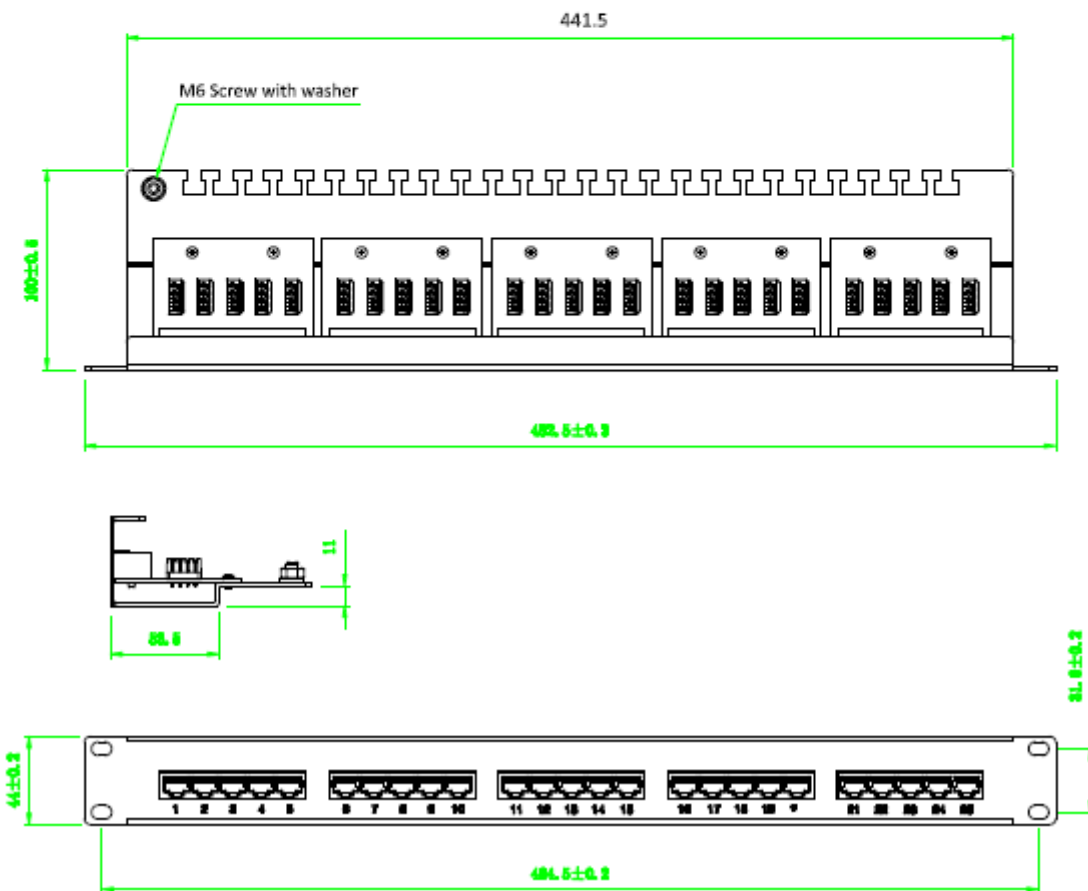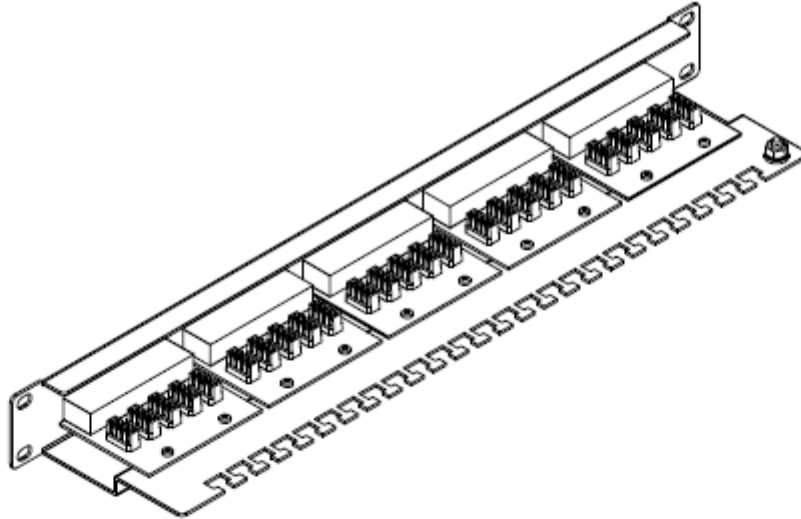

DN-91350-1

