

DIGITUS® Wall Mounting Cabinets with Swing Frame



✓ 1.1 - 1.5 strong sheet steel

✓ Safety class IP 20

✓ Standard color: Grey (RAL 7035)

✓ Large range of equipment available

Abstract

DIGITUS® Wall Mounting Cabinets, 600 mm, 600 mm depth


Features

- Safety class IP 20
- 1.1 - 1.5 strong sheet steel with a high loading capacity, powder coated
- Lockable safety-glass door with steel frame
- Side sections detachable and lockable
- Ventilation slots for active and passive ventilation and exhausting
- 483 mm (19") profile rails on the front, adjustable in depth
- Cable entry on the rear side and bottom with plastic cover and top with sliding cover
- Inclusive 8 pieces mounting screw set
- Standard color: Grey (RAL 7035); other colors available on request
- Extensive range of equipment available

Product Overview

The DIGITUS® wall mounting cabinets are made of a robust sheet steel construction with a minimum of seams. The side sections are detachable and lockable. It is fast and easy to mount the cabinet. Separately there are leveling feet or castors available. The swing frame mounted on the rear side is also lockable.

Product Images

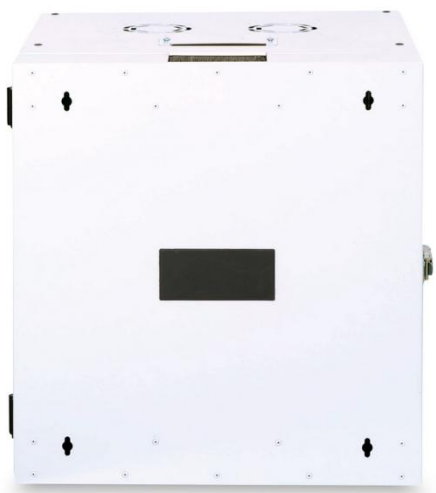

Logistic Information

Height unit (U)	Height in mm	Width x Depth in mm	Net weight in kg
7U	420 mm	600x600 mm	31.5 kg
9U	509 mm		36 kg
12U	643 mm		42.4 kg
16U	820 mm		50.8 kg
20U	998 mm		57.5 kg

Product Number Information

DN-19 07-U-3	DIGITUS® 7U wall mounting cabinet with swing frame, 420x600x600 mm, color grey (RAL 7035)
DN-19 09-U-3	DIGITUS® 9U wall mounting cabinet with swing frame, 509x600x600 mm, color grey (RAL 7035)
DN-19 12-U-3	DIGITUS® 12U wall mounting cabinet with swing frame, 643x600x600 mm, color grey (RAL 7035)
DN-19 16-U-3	DIGITUS® 16U wall mounting cabinet with swing frame, 820x600x600 mm, color grey (RAL 7035)
DN-19 20-U-3	DIGITUS® 20U wall mounting cabinet with swing frame, 998x600x600 mm, color grey (RAL 7035)