




Power Cable

Monitor to CPU, 6 ft.

Powerful connections for computing solutions.

Technical Drawing

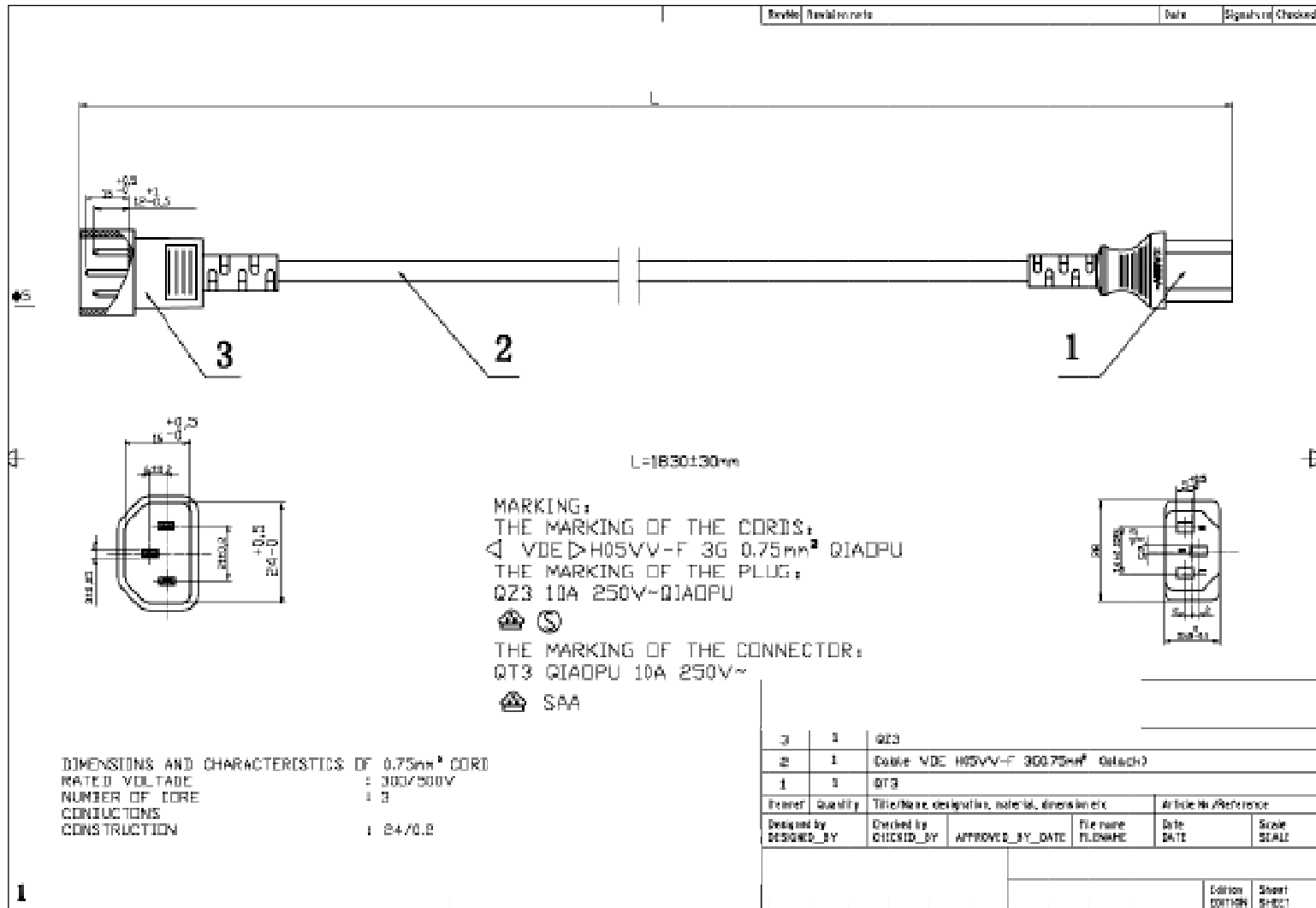

Features

- C14 male to C13 female
- Connects most monitors to a PC power supply – also serves as a power extension cable
- Molded boot with strain relief

Specifications

IEC 60320 C14, MALE

- Power: 10 A / 250 V
- Socket count: 3-blade
- Molded boot with strain relief

IEC 60320 C13, FEMALE

- Power: 10 A / 250 V
- Socket count: 3-blade
- Molded boot with strain relief

CABLE

- Strands: 24; 0.2 mm diameter
- Cores: 3; 18 AWG
- 1.8 m (6 ft.)

PACKAGE CONTENTS

- Power Cable