


RoHS & REACH Compliant



Signature	Revision History	Date	Rev.
Achy	For Bulk Productio	Aug,01,2013	00
Achy	Modify cable printing and labels information	July,08,2016	01
Achy	Optimization of drawing	May,04,2017	02

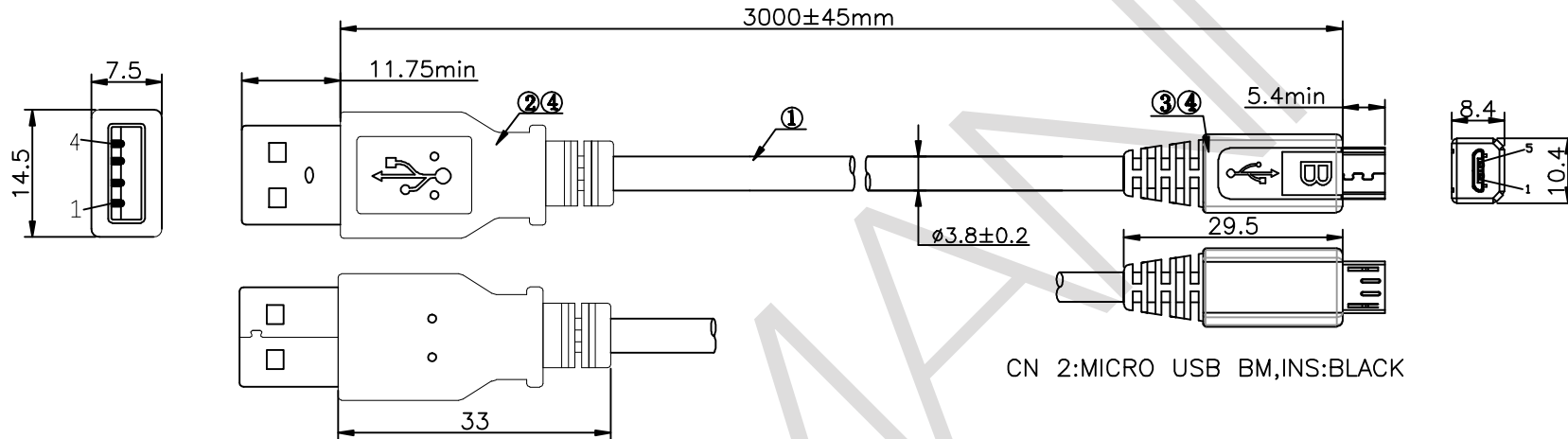

CN 1:USB2.0 AM,INS:WHITE

CN 2:MICRO USB BM,INS:BLACK

- CABLE STYLE 2725 1P*28AWG(7/0.12BC)+2C*28AWG(7/0.12BC)+ADB(48/0.12ALM), JACKET:PVC/BLACK,OD:3.8±0.2MM;CABLE MUST PRINT: AWM STYLE 2725 80°C 30V USB 2.0 High Speed Cable
- CONNECTOR:CN1:USB2.0 A/M,Insulator Color:White,Shell:Nickel Plated>Contact:Gold Plated
- CONNECTOR:CN2:USB2.0 Micro B/M,Insulator Color:Black,Shell:Nickel Plated>Contact:Gold Plated
- HOOD: MOLDED TYPE,PVC 88A,COLOR:BLACK.
- ELECTRICLE TEST:(1)100% OPEN SHORT & MISS WIRE TEST.
(2)CONDUCTOR RESISTANCE 3 ohm Max.
(3)INSULATION RESISTANCE:DC 300V 10MΩ Min
(4)HI-POT TEST:200V AC/Sec,2mA.

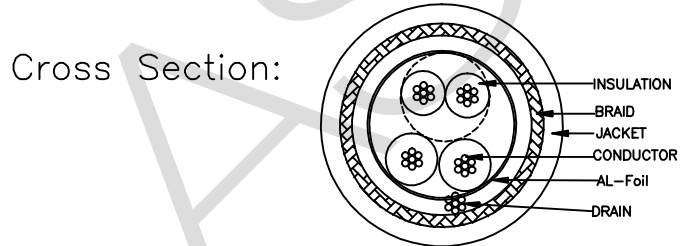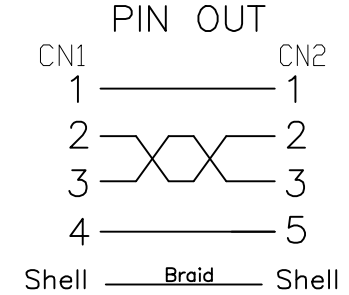

Date	Name	Part No.
May.04,2017	Achy	AK-300110-030-S
May.04,2017	Helen	EAN:4016032282976
09May, 2017	Joe	
ASSMANN Electronic GmbH		Title
		USB 2.0 connection cable,type A-micro B 3.0m,USB 2.0 conform,bl
Scale	N/A	Sheet
Unit	MM	1/2

	1	2	3	4	5	6	7																	
A	<div style="border: 2px solid green; padding: 5px; display: inline-block; color: green; font-weight: bold;">RoHS & REACH Compliant</div>					<table border="1"> <thead> <tr> <th>Signature</th> <th>Revision History</th> <th>Date</th> <th>Rev.</th> </tr> </thead> <tbody> <tr> <td>Achy</td> <td>For Bulk Productio</td> <td>Aug,01,2013</td> <td>00</td> </tr> <tr> <td>Achy</td> <td>Modify cable printing and labels information</td> <td>July,08,2016</td> <td>01</td> </tr> <tr> <td>Achy</td> <td>Optimization of drawing</td> <td>May,04,2017</td> <td>02</td> </tr> </tbody> </table>		Signature	Revision History	Date	Rev.	Achy	For Bulk Productio	Aug,01,2013	00	Achy	Modify cable printing and labels information	July,08,2016	01	Achy	Optimization of drawing	May,04,2017	02	
						Signature	Revision History	Date	Rev.															
Achy	For Bulk Productio	Aug,01,2013	00																					
Achy	Modify cable printing and labels information	July,08,2016	01																					
Achy	Optimization of drawing	May,04,2017	02																					
<h3>Package Details</h3> <p>Single Cable</p>																								
B	<table border="1"> <thead> <tr> <th>P/N</th> <th>Cable Length</th> <th>Rolling Size (Single Cable)</th> <th>Polybag Type (Single Cable)</th> <th>Bag Size (Single Cable)</th> <th>Article Weight (Single Cable)</th> </tr> </thead> <tbody> <tr> <td>AK-300110-030-S</td> <td>3.0m</td> <td>110±10mm</td> <td>Ordinary Polybag (Heat Sealed)</td> <td>200*160*0.06mm</td> <td>0.067kg</td> </tr> </tbody> </table>						P/N	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)	AK-300110-030-S	3.0m	110±10mm	Ordinary Polybag (Heat Sealed)	200*160*0.06mm	0.067kg						
P/N	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)																			
AK-300110-030-S	3.0m	110±10mm	Ordinary Polybag (Heat Sealed)	200*160*0.06mm	0.067kg																			
C	<h3>Inner Packing Unit</h3> <table border="1"> <thead> <tr> <th>P/N</th> <th>Cable Length</th> <th>Quantity (Inner Packing Unit)</th> <th>Type (Inner Packing Unit)</th> <th>Size (Inner Packing Unit)</th> <th>Weight (Inner Packing Unit)</th> </tr> </thead> <tbody> <tr> <td>AK-300110-030-S</td> <td>3.0m</td> <td>10 pcs</td> <td>Polybag (Heat Sealed)</td> <td>400*250*0.04mm</td> <td>0.675kg</td> </tr> </tbody> </table>						P/N	Cable Length	Quantity (Inner Packing Unit)	Type (Inner Packing Unit)	Size (Inner Packing Unit)	Weight (Inner Packing Unit)	AK-300110-030-S	3.0m	10 pcs	Polybag (Heat Sealed)	400*250*0.04mm	0.675kg						
P/N	Cable Length	Quantity (Inner Packing Unit)	Type (Inner Packing Unit)	Size (Inner Packing Unit)	Weight (Inner Packing Unit)																			
AK-300110-030-S	3.0m	10 pcs	Polybag (Heat Sealed)	400*250*0.04mm	0.675kg																			
D	<h3>Carton Details</h3> <table border="1"> <thead> <tr> <th>P/N</th> <th>Cable Length</th> <th>Quantity (Carton)</th> <th>Measurement (Carton)</th> <th>N.W. (Carton)</th> <th>G.W. (Carton)</th> </tr> </thead> <tbody> <tr> <td>AK-300110-030-S</td> <td>3.0m</td> <td>150 pcs</td> <td>40x38x25cm</td> <td>10.2kg</td> <td>11.0kg</td> </tr> </tbody> </table>						P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)	AK-300110-030-S	3.0m	150 pcs	40x38x25cm	10.2kg	11.0kg						
P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)																			
AK-300110-030-S	3.0m	150 pcs	40x38x25cm	10.2kg	11.0kg																			
E																								
F																								
G							<table border="1"> <thead> <tr> <th></th> <th>Date</th> <th>Name</th> <th>Part No.</th> </tr> </thead> <tbody> <tr> <td>Drawn by</td> <td>May.04,2017</td> <td>Achy</td> <td>AK-300110-030-S</td> </tr> <tr> <td>Checked by</td> <td>May.04,2017</td> <td>Helen</td> <td>EAN:4016032282976</td> </tr> <tr> <td>Approved by</td> <td>09May, 2017</td> <td>Joe</td> <td></td> </tr> </tbody> </table>			Date	Name	Part No.	Drawn by	May.04,2017	Achy	AK-300110-030-S	Checked by	May.04,2017	Helen	EAN:4016032282976	Approved by	09May, 2017	Joe	
	Date	Name	Part No.																					
Drawn by	May.04,2017	Achy	AK-300110-030-S																					
Checked by	May.04,2017	Helen	EAN:4016032282976																					
Approved by	09May, 2017	Joe																						
H	<p>★ * "ROTTERDAM" is for Sea Freight shipment * "COLOGNE" is for Air Freight shipment * "LUDENSCHIED" is for Fedex or UPS shipment</p>						<table border="1"> <thead> <tr> <th colspan="2">ASSMANN</th> <th colspan="2">Electronic GmbH</th> </tr> </thead> <tbody> <tr> <td colspan="2">Title</td> <td colspan="2">USB 2.0 connection cable,type A-micro B 3.0m,USB 2.0 conform,bl</td> </tr> <tr> <td>Scale Unit</td> <td>N/A MM</td> <td colspan="2">Sheet 1/2</td> </tr> </tbody> </table>		ASSMANN		Electronic GmbH		Title		USB 2.0 connection cable,type A-micro B 3.0m,USB 2.0 conform,bl		Scale Unit	N/A MM	Sheet 1/2					
ASSMANN		Electronic GmbH																						
Title		USB 2.0 connection cable,type A-micro B 3.0m,USB 2.0 conform,bl																						
Scale Unit	N/A MM	Sheet 1/2																						
	1	2	3	4	5	6	7																	