


USB3.0 M(A)
(BLACK COLOR)

USB3.0 M(A)
(BLACK COLOR)


ITEM NO	COLOR	LENGTH	NO.
CU0038	BLACK	1000±30MM	4052792001013
CU0039	BLACK	2000±30MM	4052792001020
CU0040	BLACK	3000±30MM	4052792001037

NOTE:

- CABLE: UL2725,AL+B-FOIL,(30AWG*1P)+[AL+MY-FOIL,(30AWG*1P+D)]*2+24AWG*2C+AB.
BLACK COLOR,OD=5.5±0.2mm,PVC JACKET.
- LENGHT: 1.0M.
- CONNECTORS:USB3.0 M(A)*2PCS(BLUE INSULATOR)(SHELL NICKEL)(PIN GOLD FLASH 15U”).
- MOLD: MOLDING TYPE.
- CONTACTS:

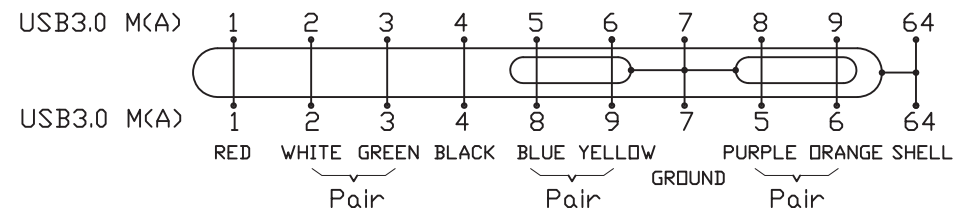

- OPEN/SHORT TEST: 100% TEST.
A.100% OPEN,SHORT&INTERMITANCE TEST.
B.CONDUCTOR RESISTANCE: 3ohms MAX:
C.INSULATION RESISTANCE: 5M Min/,10ms:
- ALL MUST BE MEET ON ROHS COMPLIANT.

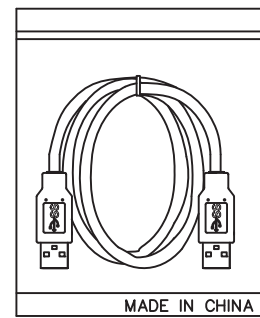

PACKING:1PCS/PE BAG+LABEL

Sticker ex:



Pantone 2945C, Black
Size: 48x150 mm R= 2mm
材質: 80P銅版紙,上亮PP(光膠)

COMPANY	2D		ITEM NO.	CU0038	NO	B6210	Part Name	USB3.0AM-AM 28/24			
REVISION	DATE	DISCRIPTION	DRAWN BY							SCALE	
REV.A/0	2012.03.21	C15-1203002	DESIGNED BY				SPEC			UNIT(mm)	
			APPROVAL BY					2direct GmbH		PAGE	1/1