 



2-Port USB Cable KVM Switch

The CS22U is a 2-port USB Cable KVM Switch that provides a simple and quick method of selecting computers – a built-in remote port selector. This allows the CS22U unit to be hidden from sight, while the remote port selector can be placed conveniently on the desktop.

The CS22U's compact all-in-one design makes it ideal for multiplatform desktop applications that require high resolution video.



Setup

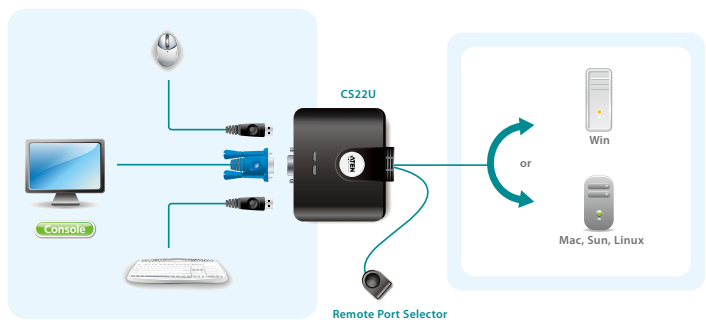

Features

- One USB console controls two USB computers
- Compact design, built-in 0.9m cables
- Supports multifunction mice
- Multiplatform support – compatible with all operation platforms PC (Windows, Linux and most others), Mac and Sun
- USB mouse port can be used for USB 1.1 hub and USB 1.1 peripheral sharing
- All-in-one design
- Superior video quality – up to 2048 x 1536; DDC2B
- Non-powered

Specifications

| Function | | CS22U | |
|----------------------|------------------------|--------------------------|-------------------------------|
| Computer Connections | | 2 | |
| Port Selection | | Remote Port Selector | |
| Connectors | Console Ports | Keyboard | 1 x USB Type A Female (Black) |
| | | Video | 1 x HDB-15 Female (Blue) |
| | | Mouse | 1 x USB Type A Female (Black) |
| | KVM Ports | Keyboard/ Mouse | 2 x USB Type A Male (Black) |
| | | Video | 2 x HDB-15 Male (Blue) |
| LEDs | Selected | 2 | |
| Cable Length | Computers | 0.9 m | |
| | Remote Port Selector | 1.8 m | |
| Video | | 2048 x 1536, DDC2B | |
| Environment | Operating Temp. | 0–50°C | |
| | Storage Temp. | -20–60°C | |
| | Humidity | 0–80% RH, Non-condensing | |
| Physical Properties | Housing | Plastic | |
| | Weight | 0.31 kg | |
| | Dimensions (L x W x H) | 7.00 x 8.20 x 2.50 cm | |

* The specifications and pictures are subject to change without notice.