



# Video Extender

Monitor your computer up to 150 meters away

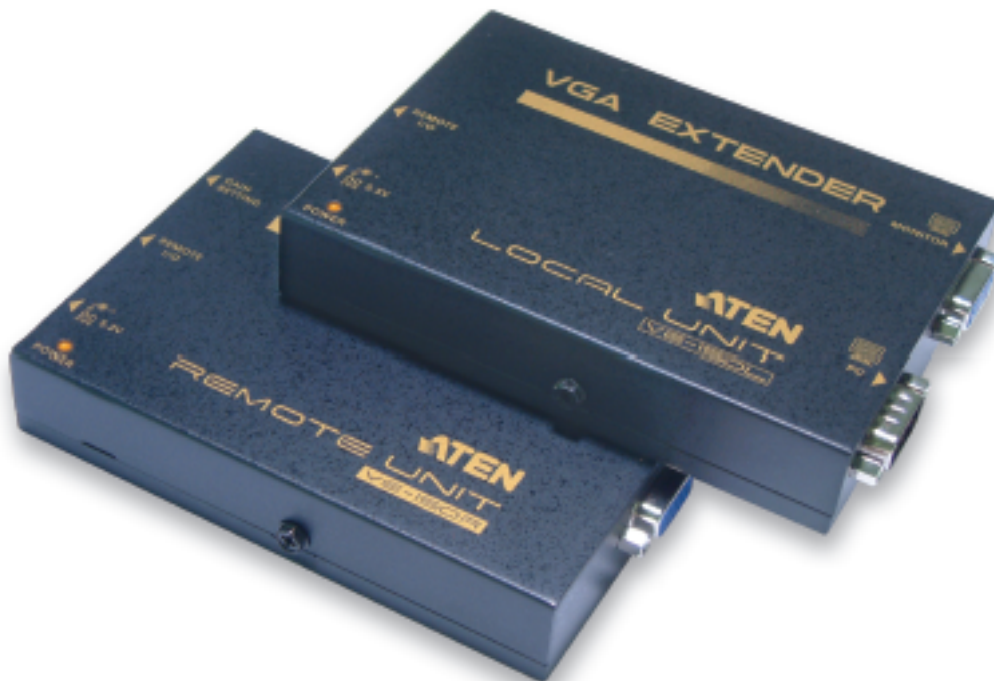

Diagram

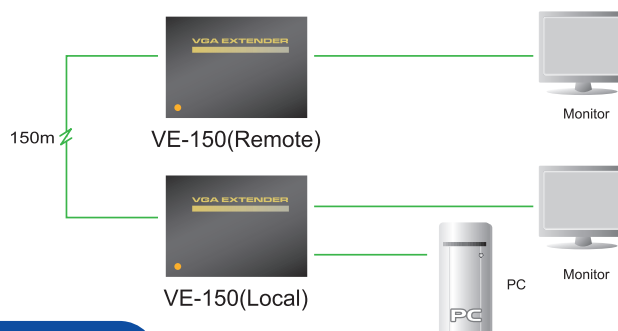

Model: **VE-150**

## Features

- Supports a local and a remote display
- Uses economical, reliable Category 5 Ethernet cable to connect the local and remote units
- Long distance transmission – up to 150m (500')
- High resolution video – up to 1280 x 1024 at 150m (500')
- 16 position adjustable video gain control to compensate for distance
- Supports VGA, SVGA, XGA, SXGA and Multisync monitors
- Supports DDC for the local monitor
- Supports PC, Mac, Sun, and Linux systems
- Easy to install

## Specifications

Function		VE-150L	VE-150R
Computer Connection		1	N/A
Connectors	Console	1 x HDB-15 female (blue)	
	Computer Link	1 x HDB-15 male (blue)	N/A
	Link	1 x RJ-45 socket	
	Power	1 x DC 5.3V jack	
Switch	Video Gain	N/A	1 x 16 position switch
LEDs	Power	1 (orange)	
Cable Length		150m [500'] (max.)	
Resolution		1280x1024, 60Hz DDC, DDC2, DDC2B*	
Power Consumption		1.2W	1.2W
Operation Temperature		0~50°C (0~80% RH, Non-condensing)	
Storage Temperature		-20°C~60°C (0~80% RH, Non-condensing)	
Housing		Metal	
Weight		250 g	250 g
Dimensions		119 x 86 x 23 mm	119 x 86 x 23 mm