

## DIGITUS® Category 6 Class E, U-UTP Twisted Pair Patch Cable - PVC




- ✓ PVC
- ✓ Boot with kink protection
- ✓ Red plug for CAT 6
- ✓ Various lengths and colors

### Abstract

DIGITUS® Category 6 Class E, U-UTP Twisted Pair Patch Cable, Cu, PVC, AWG 26/7, various lengths and colors

### Features

- 2x RJ45 connectors
- Boots with kink protections and strain reliefs
- Spot length on boot
- Material: Cu
- UL certificated
- Category: CAT 6 Class E
- Shielding: U-UTP, unshielded
- Structure: 4x 2 AWG 26/7, twisted pair
- Configuration: 1:1
- Sheath: PVC
- Various lengths and colors available

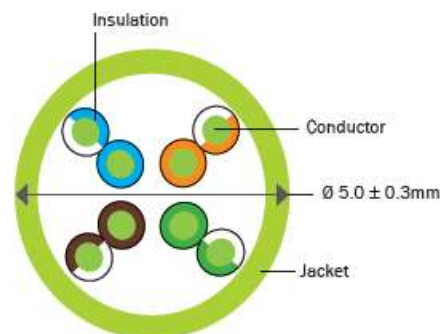

### Product Overview

The new DIGITUS® Category 6 Class E, U-UTP patch cables are manufactured and tested to the ISO/IEC 11801 and DIN EN 50173 Category 6 specifications. DIGITUS® patch cables will guarantee the installed cabling system is compliant with the ISO & EN channel specification requirements and will provide optimum performance levels of DIGITUS® Category 6 cabling.

The patch cables have a new reworked plug with bend and latch protection, which prevents the snagging of the cable and also protects the latching lever against breaking. You can easily identify the Category 6, because of the new red colored connector.

### Performance Overview

DIGITUS® Category 6 Class E, U-UTP patch cables are manufactured acc. to ISO/IEC and DIN standards.

The performance characteristics are tested up to 250 MHz inclusive the NEXT and ELFEXT return loss.

DIGITUS® patch cables are designed and produced to fulfill the highest requirements of various application areas in full volume.

### Performance- and Specification Overview

Conductor	AWG 26/7 bare copper, 7/0.15 ± 0.015 mm
Color code	Orange x White, Green x Whit, Blue x White, Brown x White
Insulations	HD-PE (High Density Polyethylene)
Outer sheath	PVC
Overall diameter	5.0 mm ± 0.3 mm
RJ45 connector	3 μ minimum gold-plated in confined area (gold flash over remainder) over 60 μ nickel undercoat
Durability	750 insertion cycles
Contact resistance	230 Ω maximum
Resistance unbalance	2% maximum
Dialectric strength	2500 VDC for 3 seconds
Uninsulated resistance	150 MΩ/km minimum
Operating temperature	-20 °C up to +60 °C
Colors	Various colors available on request
Marking	Brand name, cable length and cable information


### Transmission Properties

Freq.	Insertion Loss	NEXT	RL	ACR-N	ACR-F	PS NEXT	PS ACR-N	PS ACRF
MHz	dB	dB	dB	dB	dB	dB	dB	dB
1.00	4.00	65.00	19.00	61.00	63.30	62.00	58.00	60.30
4.00	4.20	63.00	19.00	58.90	51.20	60.50	56.40	48.20
8.00	5.90	58.20	19.00	52.30	45.20	55.60	49.70	42.20
10.00	6.60	56.60	19.00	50.00	43.30	54.00	47.40	40.30
16.00	8.30	53.20	18.00	44.90	39.20	50.60	42.30	36.20
20.00	9.30	51.60	17.50	42.30	37.20	49.00	39.70	34.20
25.00	10.50	50.00	17.00	39.60	35.30	47.30	36.90	32.30
31.25	11.70	48.40	16.50	36.70	33.40	45.70	34.00	30.40
62.50	16.90	43.40	14.00	26.50	27.30	40.60	23.70	24.30
100.00	21.70	39.90	12.00	18.20	23.30	37.10	15.40	20.30
200.00	31.70	34.80	9.00	3.10	17.20	31.90	0.10	14.20
250.00	35.90	33.10	8.00	-2.80	15.30	30.20	-5.80	12.30

The results of the chart above are typical for Category 6 Class E, patch cables 2 m, 5 m up to 10 m length

### Product Number Information


#### Category 6 U-UTP Cable Assemblies

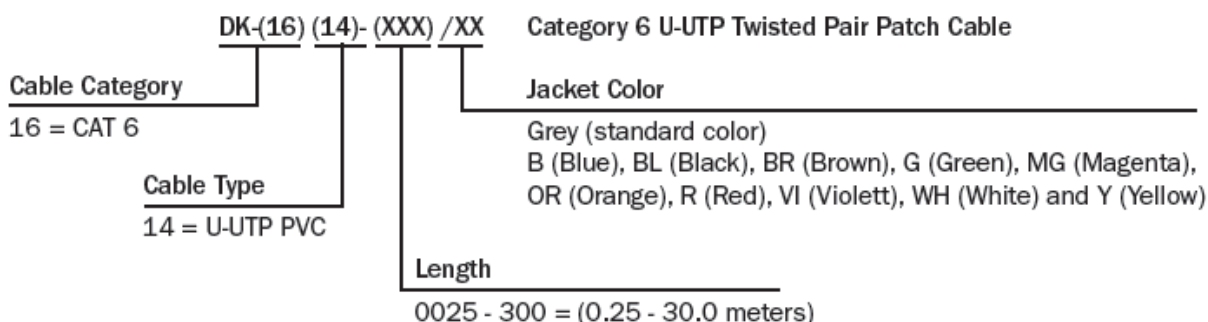

### Length Tolerances

Length (m)	Tolerance (mm)
0.15	+20/-6
0.25	+20/-6
0.5	+20/-10
0.75	+20/-13
1	+/-20
1.5	+/-30
2	+/-40
2.5	+/-50
3	+/-60
4	+/-90
5	+/-110
6	+/-120
7	+/-140
7.5	+/-150
8	+/-155
10	+/-200
12	+/-250
13	+/-270
15	+/-310
20	+/-400
25	+/-500
30	+/-630
40	+/-840
50	+/-1000
70	+/-1300
75	+/-1500
100	+/-1800

### Technical Drawing

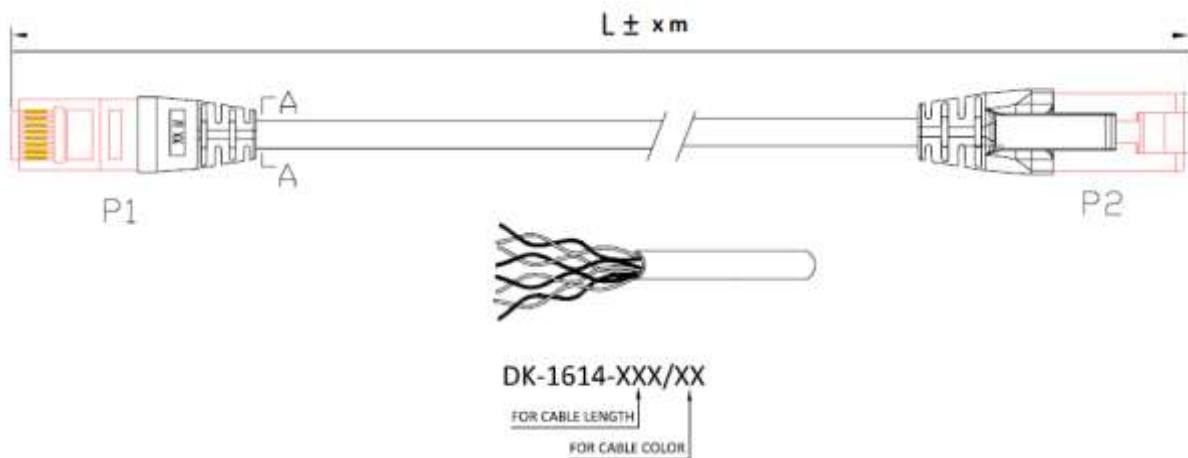

**DIGITUS Professional DIGITUS CAT 6 U-UTP patch cable**

DK-1614-030/G 4016032315933



**CAT 6 U-UTP patch cable, PVC, Cu**  
**AWG 26/7, Length 3.0m , color green**

**Best performance and link quality for your network.**

The new DIGITUS® Patch Cable series is back with a reworked plug on the market. The bend protection sleeve with latch protection prevents snagging the cable and also protects the latching lever before break. The connector can be different in color depending on the category: A blue plug for CAT5e, a red plug for CAT6 and a yellow plug for CAT6A. We also offer a variety of different colors and lengths to meet all demands. For more information, please see our Patch Cable brochure!

- 1 2 x RJ45 connectors
- 1 Plugs with new design
- 1 Boots with kink protections and strain reliefs
- 1 Spot length on boot
- 1 Material: Cu
- 1 UL certified
- 1 Category: CAT 6
- 1 Shielding: U-UTP, unshielded
- 1 Structure: 4 x 2 AWG 26/7, twisted pair
- 1 Color: green
- 1 Length: 3.0 m
- 1 Configuration: 1:1
- 1 Jacket: PVC
- 1 Packaging: DIGITUS Polybag

**DIGITUS Professional DIGITUS CAT 6 U-UTP patch cable**

DK-1614-030/G 4016032315933

→ **Logistics**

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm <sup>3</sup>
Packaging Unit Carton	120	12,80	41,00	41,00	26,00	43706,00
Packaging Unit Inside	10	1,07	9,00	26,00	16,00	3744,00
Packaging Unit Single	1	0,11	3,00	13,50	25,00	1012,50
Net single without Packaging	1	0,00	0,00	0,00	0,00	0,00

→ **Packaging type**

