
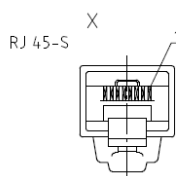
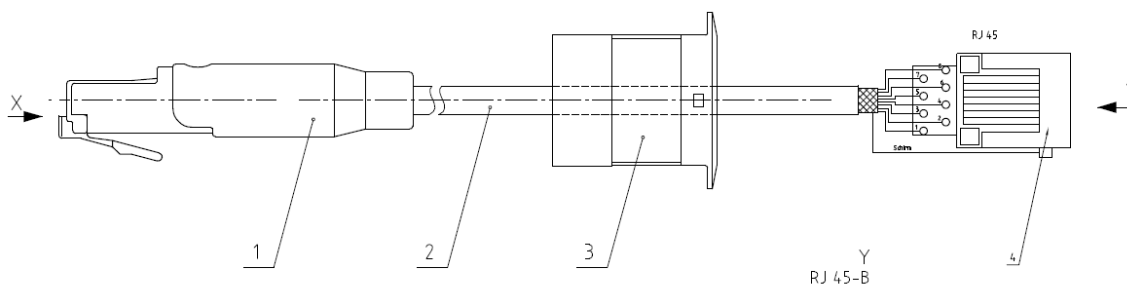
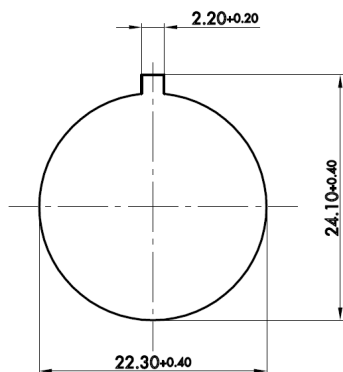


Date: 04-July-2013


## R(R)(Q)J(VA)\_RJ45(\_Colour)(\_Length in CM)

### Technical Data

Type reference:	R(R)(Q)J(VA)_RJ45(_Colour)(_Length in CM)
Front jack:	RJ45 jack
Rear connector:	RJ45 connector
Cable:	Cat 5
Length:	if not specified, 60cm as a standard
Housing colour:	if not specified, titanium lacquered SW= black
Degree of protection:	IP65
Mounting hole:	22.3mm
Max. operating temperature:	-20°C ... 60°C
Max. storage temperature:	-25°C ... 80°C

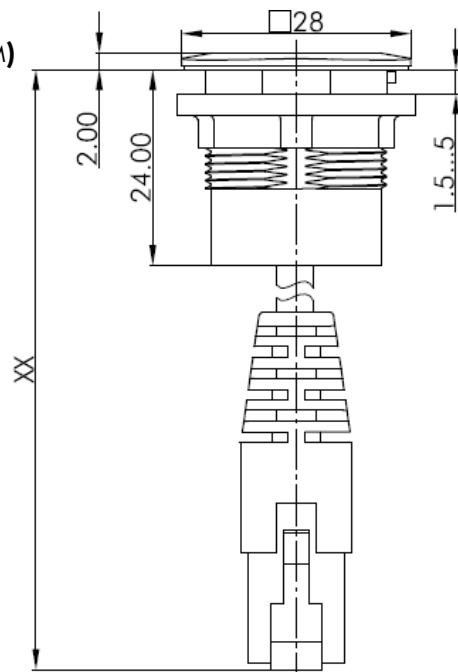

RJ 45-S	RJ 45-B
1	1
2	2
3	3
4	4
5	5
6	6
7	7
8	8

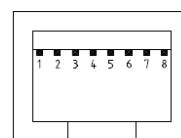

Subject to modifications -