



19" Fan Unit with 2 Fans or 4 Fans

Technical Features

1.5mm steel

Air flow 95-115 CFM

Operating voltage AC220-240v, 50/60Hz


Fan speed 2700-3100 rpm

Noise level 44-49dB(A)

| Part-No. Black = B Grey = G | Height U | Width (W) mm | Weight kg | Number of Fans | EAN Code |
|-----------------------------------|-------------|-----------------|--------------|-------------------|---------------|
| FAU02FB | 1U | 483 | 3.5 | 2 | 4052792026788 |
| FAU02FG | 1U | 483 | 3.5 | 2 | 4052792026771 |
| FAU04FB | 1U | 483 | 4 | 4 | 4052792026801 |
| FAU04FG | 1U | 483 | 4 | 4 | 4052792026795 |

Technical Drawings

FAU02FB/FAU02FG

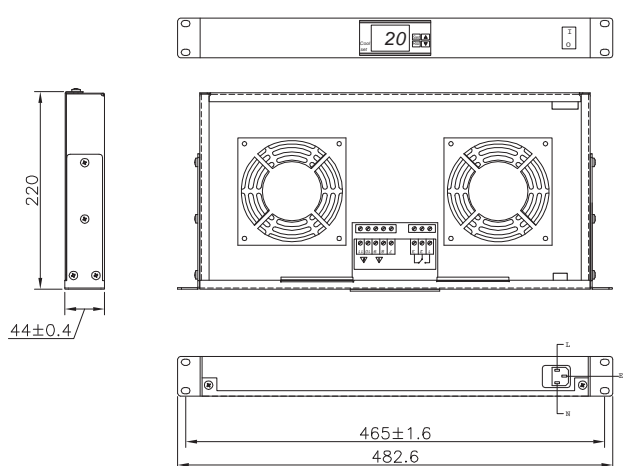

www.logilink.com




RoHS
compliant



Made in China

* The specifications and pictures are subject to change without notice.
*All trade names referenced are the registered trademark of their respective owners.

FAU04FB/FAU04FG

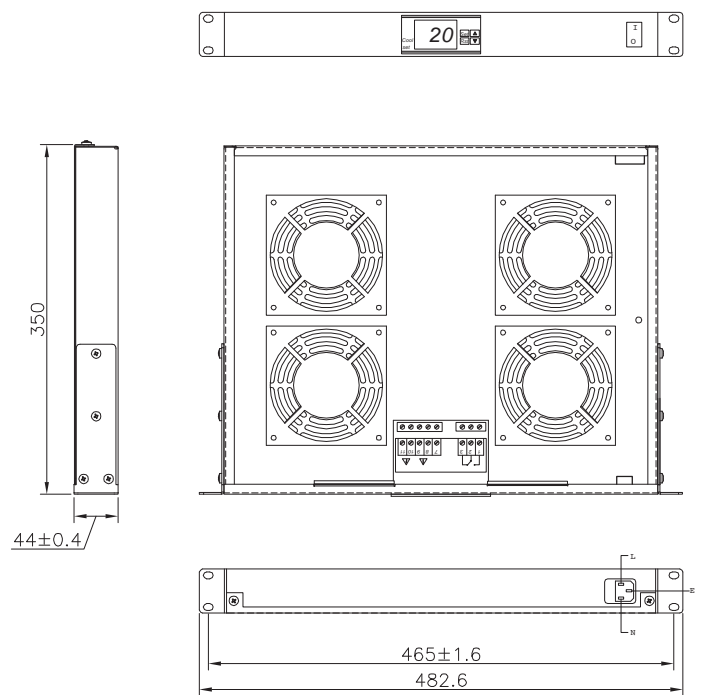

Package Contents

1 x 19" Fan unit

Packaging Informations

| | |
|-------------------|---|
| Packing Dimension | 505 x 230 x 55mm (FAU02Fx) / 505 x 360 x 55mm (FAU04Fx) |
| Packing Weight | 3.5kg (FAU02Fx) / 5.2kg (FAU04Fx) |
| Carton Dimension | 505 x 230 x 55mm (FAU02Fx) / 505 x 360 x 55mm (FAU04Fx) |
| Carton Q'ty | 1pc |
| Carton Weight | 3.5kg (FAU02Fx) / 5.2kg (FAU04Fx) |