

## U/UTP Patch Cable Cat.5e

### Technical Features

CCA Wire


 
Category 5e U/UTP AWG 26/7

PVC Jacket


Unshielded

TIA/EIA 568B

### Technical Drawings

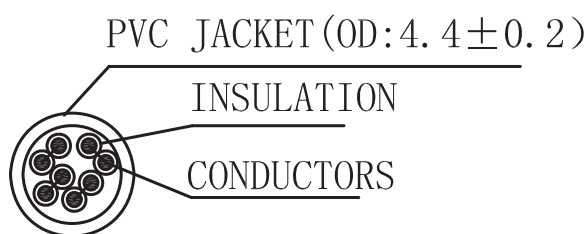

SECTION A-A

 

[www.logilink.de](http://www.logilink.de)



RoHS  
compliant




Length	Grey	EAN Code
0.25 m	CP1012U	4052792025514
0.50 m	CP1022U	4052792025521
1.00 m	CP1032U	4052792025538
2.00 m	CP1052U	4052792025545
3.00 m	CP1062U	4052792025552
5.00 m	CP1072U	4052792025569
7.50 m	CP1082U	4052792025576
10.00 m	CP1092U	4052792025583
15.00 m	CP1102U	4052792025590
20.00 m	CP1112U	4052792025606
30.00 m	CP1122U	4052792026047
50.00 m	CP1142U	4052792026054



Length	Black	EAN Code	Red	EAN Code
0.25 m	CP1013U	4052792025613	CP1014U	4052792025712
0.50 m	CP1023U	4052792025620	CP1024U	4052792025729
1.00 m	CP1033U	4052792025637	CP1034U	4052792025736
2.00 m	CP1053U	4052792025644	CP1054U	4052792025743
3.00 m	CP1063U	4052792025651	CP1064U	4052792025750
5.00 m	CP1073U	4052792025668	CP1074U	4052792025767
7.50 m	CP1083U	4052792025675	CP1084U	4052792025774
10.00 m	CP1093U	4052792025682	CP1094U	4052792025781

Length	Green	EAN Code
0.25 m	CP1015U	4052792025798
0.50 m	CP1025U	4052792025804
1.00 m	CP1035U	4052792025811
2.00 m	CP1055U	4052792025828
3.00 m	CP1065U	4052792025835
5.00 m	CP1075U	4052792025842
7.50 m	CP1085U	4052792025859
10.00 m	CP1095U	4052792025866

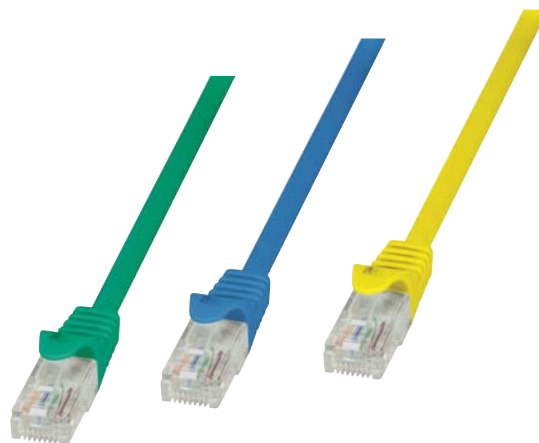

Length	Blue	EAN Code	Yellow	EAN Code
0.25 m	CP1016U	4052792025873	CP1017U	4052792025958
0.50 m	CP1026U	4052792025880	CP1027U	4052792025965
1.00 m	CP1036U	4052792025897	CP1037U	4052792025972
2.00 m	CP1056U	4052792025903	CP1057U	4052792025989
3.00 m	CP1066U	4052792025910	CP1067U	4052792025996
5.00 m	CP1076U	4052792025927	CP1077U	4052792026009
7.50 m	CP1086U	4052792025934	CP1087U	4052792026016
10.00 m	CP1096U	4052792025941	CP1097U	4052792026023

## Package Contents

U/UTP Patch Cable Cat.5e x 1

## Packaging Informations

Packing Dimension	140 x 180mm (0.25m - 1m items) / 160 x 200mm (2m - 3m items) / 180 x 230mm (5m - 10m items) / 220 x 260mm(15m - 20m items) / 260 x 300mm(30m items) / 300 x 330mm(50m items)
Packing Weight	0.014kg (0.25m items) / 0.18kg (0.5m items) / 0.024kg (1m items) / 0.0425kg (2m items) / 0.0533kg (3m items) / 0.08kg (5m items) / 0.116kg (7.5m items) / 0.16kg (10m items) / 0.25kg (15m items) / 0.3kg (20m items) / 0.5kg (30m items) / 0.75kg (50m items)
Carton Dimension	40 x 30 x 44mm (0.25m items) / 40 x 30 x 48mm (0.5m items) / 40 x 30 x 38mm (1m, 50m items) / 40 x 30 x 40mm (2m / 3m items) / 40 x 30 x 42mm(5m items) / 40 x 30 x 48mm (7.5m - 10m items) / 40 x 30 x 37mm (15m, 30m items) / 40 x 30 x 32mm (20m items)
Carton Q'ty	500pcs (0.25m - 0.5m items) / 250pcs (1m items) / 200pcs (2m items) / 150pcs (3m items) / 100pcs (5m items) / 60pcs (7.5m items) / 50pcs (10m items) / 40pcs (15m items) / 30pcs (20m items) / 20pcs (30m items) / 14pcs (50m items)
Carton Weight	10kg (0.25m, 2m, 3m items) / 8.5kg (1m items) / 10.5kg (5m items) / 9kg (7.5m items) / 9.5kg (10m items) / 11kg (15m - 30m items) / 12kg (50m items)

