



DATA SHEET	61805300
QUADRO Set	valid from : 18.12.2003

This tool unites four functions:

Stripping - Twisting - Crimping - Cutting

Ergonomic and function have been set great store by which makes quick and precise stripping and pressing on connector sleeves possible.


JOKARI Quadro has got its use for all electrical installations (electrical function boxes), electrical service etc. It is suitable for PVC-insulated conductors.

The selfadjusting blades will not cause any damage to the conductor. The integrated twisting device prevents splaying of wire strands to enable easy insertion in connector sleeves. The trapezium crimping occurs according to VDE 0609, part I, and is very easy. Changing the magazine takes only seconds.

All current connector sleeves from 0,5 up to 2,5 mm² (in stripes) can be used. The side cutter is suitable for wires up to 2,5 mm Ø.

Wear-parts can be changed because the solid assembly is screwed.

Outstanding there is the weight of only 220 g.

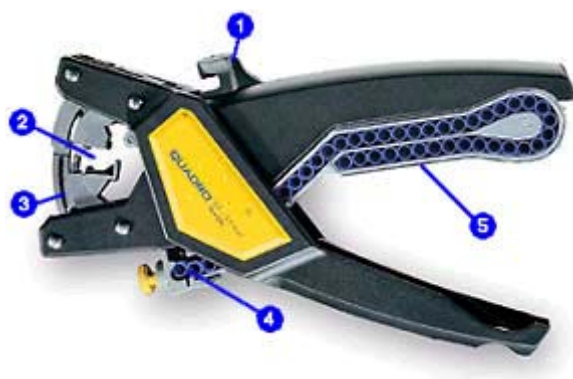

- 1) Side cutter, max. 2,5 mm Ø
- 2) Wire stopper for perfect length
- 3) Selfadjusting stripping device for all flexible cables of 0,5 up to 2,5 mm² (AWG 20 up to 14) with outer sheath of PVC
- 4) Twisting device prevents splaying of wire strands to enable easy insertion in connector sleeves. Crimping of insulated ferrules in stripes from 0,5 up to 2,5 mm² (AWG 20 up to 14) according to VDE 0609 part I
- 5) Quick change sleeve magazine for all usual connector sleeves in stripes of 0,5 - 0,75 - 1,0 - 1,5 - 2,5 mm²

Technical data

Art.-Nr.	description
61805300	QUADRO Set
61805301	QUADRO
61805302	QUADRO magazine






DATA SHEET	61805300
QUADRO Set	valid from : 18.12.2003

DIN-strips for QUADRO

Insulated conductor end sleeves in strips DIN 46228, part 4 for QUADRO.

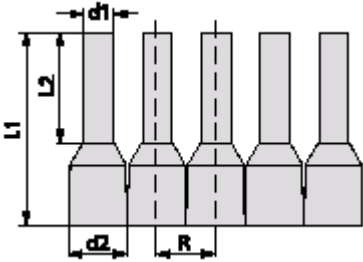

Part number	Type	Core cross-section mm ²	AWG	Colour	L1 mm	L2 mm	d1 mm	d2 mm	R mm	Pieces per PU
6180 5170	DIN-Bandware 0,50	0,50	20	white	14,5	8	1,1	2,6	3,5	500
6180 5180	DIN-Bandware 0,75	0,75	20	gray	14,5	8	1,3	2,8	3,6	500
6180 5190	DIN-Bandware 1,00	1,00	18	red	14,5	8	1,5	3,0	3,9	500
6180 5200	DIN-Bandware 1,50	1,50	16	black	14,5	8	1,8	3,4	4,2	500
6180 5210	DIN-Bandware 2,50	2,50	14	blue	14,5	8	2,3	4,2	5,0	500