


U.I. Lapp GmbH	DATASHEET	
	DIN-Coil conductor end sleeves	61802054 14.11.2013

Insulated conductor end sleeves in strips/coils

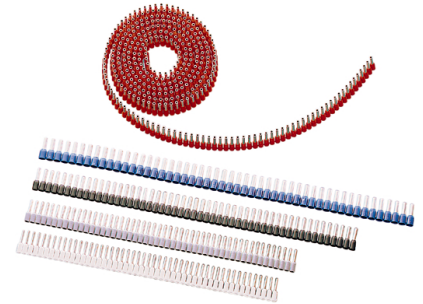

Halogen-free



Application range

Insulated conductor end sleeves in strips, DIN 46228, Part 4
DIN strips, available in coils of up to 3000 items for working with automatic crimping machines

Included

Coil diameter: approx. 25 cm

Remark


Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

Article designation:	DIN coil 0.75
For mm ² :	0,75
Colour:	grey
l1 mm:	14.5
l2 mm:	8
d1 mm:	1.3
d2 mm:	2.8
R mm:	3.6
Contents (unit):	3000 x 1
Material:	Copper/PP Surface: tin-plated
Temperature range:	Permanent load -5°C up to +105°C, temporary load +120°C

Product Management	Document: DIN-Coil conductor end sleeves	1 / 2
--------------------	--	-------

U.I. Lapp GmbH	<h1>DATASHEET</h1>	 LAPP GROUP
	DIN-Coil conductor end sleeves	61802054 14.11.2013

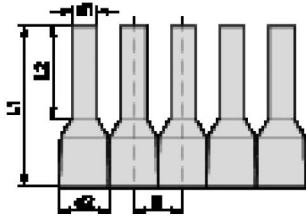

Product Management	Document: DIN-Coil conductor end sleeves	2 / 2
--------------------	--	-------