

U.I. Lapp GmbH	<h1>DATASHEET</h1>	
	EPIC® H-A 10 TS	10445000 14.11.2013

These connectors are attractive because of their compact housing.
Small and space-saving for narrow available space



Industrial machinery and plant engineering



Mechanical resistance



Robust



Waterproof



Info

Compact, robust metal housings size H-A 10

Application range

Machine and equipment manufacturing
Control engineering
Electronic laboratory

Product features

Hood, low version
Bolts for single lever
Side cable entry
Versions with neck

Remark


Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

Article:	H-A 10 TS 16
PG:	16
Neck:	yes
Pieces / PU:	5
Material:	Housing: aluminium alloy, grey Lever: zinc-plated steel Sealing: NBR
Protection rating:	IP 65 (latched)
Temperature range:	-40 °C to +100 °C, short-term up to +125 °C

Product Management	Document: EPIC® H-A 10 TS	1 / 2
--------------------	---------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	EPIC® H-A 10 TS	10445000 14.11.2013

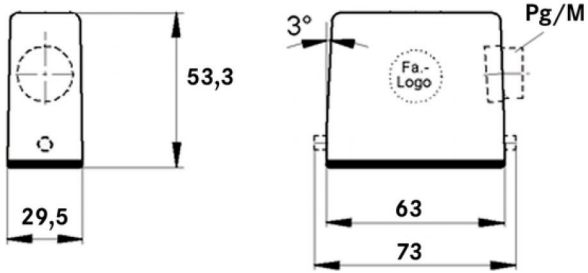

Product Management	Document: EPIC® H-A 10 TS	2 / 2
--------------------	---------------------------	-------