

U.I. Lapp GmbH	DATASHEET	
	EPIC® H-A 16 TSH	70492200 14.11.2013

These connectors are attractive because of their compact housing.
Small and compact, for applications with high number of contacts



Industrial machinery and plant engineering



Mechanical resistance



Robust



Waterproof



Info

Compact, robust metal housings size H-A 16

Application range

Machine and equipment manufacturing
Control engineering
Electronic laboratory

Product features

Hood, high version
Bolts for single lever
Side cable entry
Versions with / without neck

Remark



Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

Article:	H-A 16 TSH 16
PG:	16
Neck:	yes
Pieces / PU:	5
Material:	Housing: powder-coated aluminium alloy, grey Sealing: NBR
Protection rating:	IP 65 (latched)
Temperature range:	-40 °C to +100 °C, short-term up to +125 °C

Product Management	Document: EPIC® H-A 16 TSH	1 / 2
--------------------	----------------------------	-------

U.I. Lapp GmbH	<h1>DATASHEET</h1>	
	EPIC® H-A 16 TSH	70492200 14.11.2013

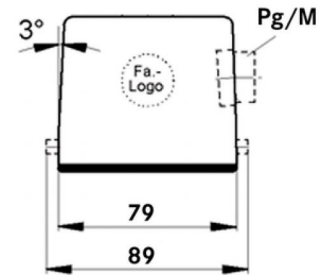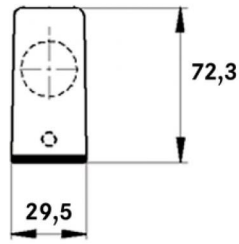

Product Management	Document: EPIC® H-A 16 TSH	2 / 2
--------------------	----------------------------	-------