


U.I. Lapp GmbH	DATASHEET	
	EPIC® H-B 10 SDR-BO	19036100 14.11.2013

Housing design H-B. The industry standard.
The smallest housing with single and double lever. The right housing is available for every application

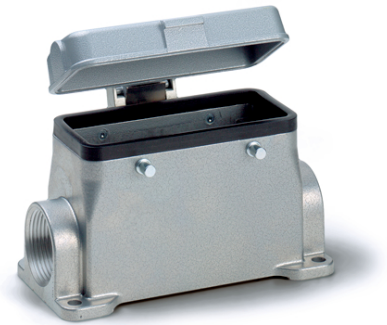

Automation



Industrial machinery and plant engineering



Mechanical resistance



Robust



Waterproof

Info

Universal, robust metal housings size H-B 10

Application range

Plant engineering
Light & sound technology
Plastics industry

Product features

Surface-mount base, low version
Bolts for double lever
1 cable entry
Metal cover

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

Article:	H-B 10 SDR-BO M25
M:	25
Pieces / PU:	10
Material:	Housing: powder-coated aluminium alloy, grey Lever: zinc-plated steel Sealing: NBR
Protection rating:	IP 65 (latched)
Temperature range:	-40 °C to +100 °C, short-term up to +125 °C

Product Management	Document: EPIC® H-B 10 SDR-BO	1 / 2
--------------------	-------------------------------	-------

