

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	EPIC® H-D 8	11253500 14.11.2013

H-D inserts for stamped and machined crimp contacts
 Small, high-performance connector
 PE contact with screw connection
 High performance crimping contacts



Industrial machinery and plant engineering

Info

Compact, powerful standard insert
 Space saving, crimping contact

Application range

Machine and equipment manufacturing
 Control engineering

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

Article:	H-D 8 BCM
Version:	female
Contacts:	1 - 8
Pieces / PU:	10
Rated voltage (V):	IEC: 24 V (AC)/60 V (DC) metal housing 250 V thermoplastic housing
	UL: 250 V
Rated impulse voltage:	2.5 kV
Rated current (A):	IEC: 10 A UL: 10 A
Contact resistance:	< 2 mOhm
Contacts:	Copper alloy, hard silver/gold-plated
Number of contacts:	8
Termination methods:	Crimp termination: 0.14 - 2.5 mm²
Cycle of mechanical operation:	100
Temperature range:	-40 °C to +100 °C, short-term up to +125 °C
VDE-tested:	Certified production control: VDE-REG. no.: B437 UL-tested: UL File Number: E75770
Degree of soiling:	3




Product Management	Document: EPIC® H-D 8	1 / 2
--------------------	-----------------------	-------



U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	EPIC® H-D 8	11253500 14.11.2013





M

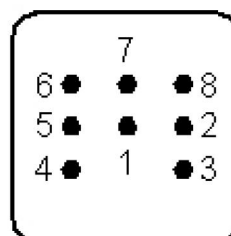


F

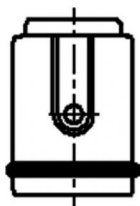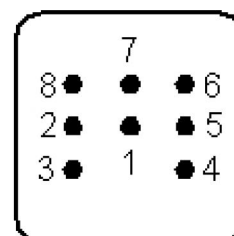

M

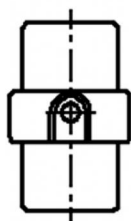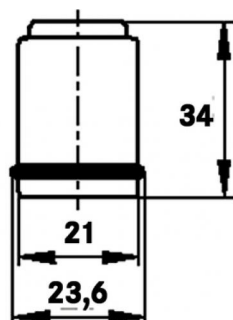

F

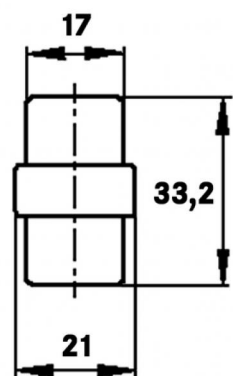

Product Management	Document: EPIC® H-D 8	2 / 2
--------------------	-----------------------	-------