

| | | |
|-------------------|--------------------|--|
| U.I. Lapp GmbH | DATASHEET |  |
| | EPIC® H-Q 5 | 10431500 14.11.2013 |

With five working contacts in the proven crimp technology and one PE contact with screw termination.
High performance crimping contacts
PE contact with screw connection



Industrial machinery and plant engineering

Info

Compact, powerful standard insert
Space saving, crimping contact

Application range

Machine and equipment manufacturing
Control engineering

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

| | |
|--------------------------------|---|
| Article: | H-Q 5 SC |
| Version: | male |
| Contacts: | 1 - 5 |
| Pieces / PU: | 10 |
| Rated voltage (V): | IEC: 230 V / 400 V UL: 600 V CSA: 600 V |
| Rated impulse voltage: | 4 kV |
| Rated current (A): | IEC: 16 A UL: 16 A CSA: 16 A |
| Contact resistance: | < 2 mOhm |
| Contacts: | Copper alloy, hard silver/gold-plated |
| Number of contacts: | 5 + PE |
| Termination methods: | Crimp termination: 0.5 - 2.5 mm² |
| Cycle of mechanical operation: | 100 |
| Temperature range: | -40 °C to +100 °C, short-term up to +125 °C |
| Degree of soiling: | 3 |




| | | |
|--------------------|-----------------------|-------|
| Product Management | Document: EPIC® H-Q 5 | 1 / 2 |
|--------------------|-----------------------|-------|



| | | |
|-------------------|-------------|--|
| U.I. Lapp GmbH | DATASHEET |  LAPP GROUP |
| | EPIC® H-Q 5 | 10431500 14.11.2013 |




M

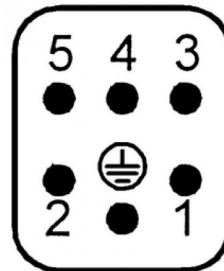



F

 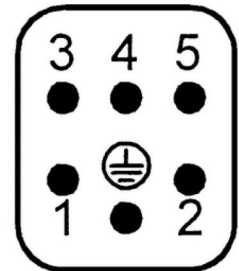

F

 

M

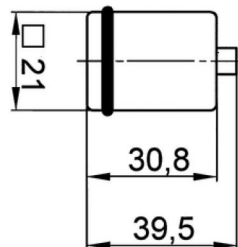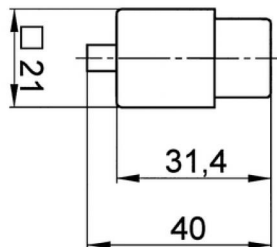

| | | |
|--------------------|-----------------------|-------|
| Product Management | Document: EPIC® H-Q 5 | 2 / 2 |
|--------------------|-----------------------|-------|