


DIGITUS® Plug&View OptiDome Pro

DN-16043
EAN 4016032337348



More information
about this product
in your language
with QR-code or on
www.plug-view.com

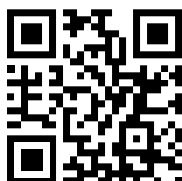

DIGITUS® Plug&View app
for Apple iOS and Google Android



DIGITUS® Plug&View OptiDome Pro

More safety for your home. The DIGITUS® Plug&View OptiDome Pro is part of the new DIGITUS® Plug&View generation and was designed specifically for outdoor use. The plastic dome including the bordering is extremely shock-resistant and protected against sabotage. Consider to mount OptiDome under the ceiling of small warehouses or your carport. Equipped with infrared LEDs the weatherproof camera provides the optimal day & night surveillance. Always have an eye on what is important. With DIGITUS® Plug&View technology the installation of your OptiDome Pro is done in 3 easy steps. Everything just works with DIGITUS® Plug&View.

- 2 megapixel video resolution (UXGA 1600 x 1200, HD720 1280 x 720)
- Low-latency video streaming with H.264 compression format
- Powerful mobile surveillance supporting iOS and Android devices
- Wireless LAN according to the newest 11n standard for fluent image transmission
- IP66 housing design for outdoor use
- Suitable for the most common browsers
- Simple and fast installation with P2P support & QR-code-scanning
- IR-LEDs and IR cut filter included for day & night surveillance
- LAN Speed: 10/100Base-TX Ethernet
- Supports up to 25fps video frame rate at HD720 and 15fps at UXGA
- Integrated 2GB storage for recording videos and snapshots
- Advanced motion detection, record and save events via email/FTP/Google Drive
- Operating temperature: -10°C ~+50°C
- Power source (±10%): DC12V / 1A
- Power over Ethernet
- Dimensions (mm): 140 (L) x 140 (W) x 110 (H)
- Supports DIGITUS® Plug&View app for smart phone and tablet access
- Operating system independent, supports e.g. Windows, Mac OS, Linux and Sun
- Lens: F1.4 f2.8-12mm
- Horizontal viewing angle: 20° - 65°

Your wireless outdoor Plug&View IP camera with IP66 housing and optical zoom

- 3 easy installation steps: 1. Establish network connection, 2. Install app or register camera on www.plug-view.com, 3. Ready to go!
- Outdoor dome camera for day & night use with varifocal lens for optical zoom
- Low-latency video streaming with H.264 compression format

Package content:

- IP camera
- Product support CD-ROM
- Patch cable
- Mounting kit
- Power supply

