


U.I. Lapp GmbH	<b>DATASHEET</b>	
	<b>SKINDICHT® BL-M hexagonal</b>	52103425 14.11.2013

For closing pre-threaded holes  
High degree of protection

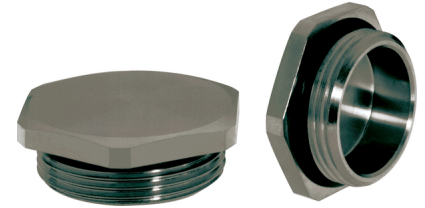

Corrosion-resistant



Robust



Reliability



Temperature-resistant

### Application range

Machine and equipment manufacturing  
Electric motor manufacturing

### Design

Metric connection thread acc. to EN 50262

### Note

Dummy plug made of chromium nickel steel on request

### Remark

Viton® is a registered trademark of DuPont de Nemours

Photographs are not to scale and do not represent detailed images of the respective products.

### Technical Data

Article designation / size:	20 x 1,5
SW (mm):	24
Outer Ø (mm):	26,4
Pieces / PU:	50
On request:	VITON® O-ring -20 °C to +200 °C
Material:	Body: nickel-plated brass O-ring: NBR
Protection rating:	IP 68
Temperature range:	-30°C to +100°C

Product Management	Document: SKINDICHT® BL-M hexagonal	1 / 1
--------------------	-------------------------------------	-------