

|                   |                        |                                                                                                      |
|-------------------|------------------------|------------------------------------------------------------------------------------------------------|
| U.I. Lapp<br>GmbH | <b>DATASHEET</b>       |  <b>LAPP GROUP</b> |
|                   | <b>SKINDICHT® CN-M</b> | <b>52032600</b><br><b>14.11.2013</b>                                                                 |

For high temperatures  
Resistant to oils, solvents, acids and chemicals  
Seawater-resistant  
For high mechanical stress  
High corrosion-resistance



Good chemical resistance



Corrosion-resistant



Mechanical resistance



Robust



Temperature-resistant

### Application range

Chromium nickel steel cable gland with VITON® seal, specially designed for use under tough conditions.  
Pharmaceutical and petrochemical industry  
Offshore sector  
Wind power plants  
Brickworks

### Design

Metric connection thread acc. to EN 50262

### Note

Refer to the chart to find a suitable counter-nut for SKINDICHT® SM CrNi M

### Remark

Viton® is a registered trademark of DuPont de Nemours  
Photographs are not to scale and do not represent detailed images of the respective products.

|                    |                           |       |
|--------------------|---------------------------|-------|
| Product Management | Document: SKINDICHT® CN-M | 1 / 3 |
|--------------------|---------------------------|-------|


|                   |                        |                                                                                                      |
|-------------------|------------------------|------------------------------------------------------------------------------------------------------|
| U.I. Lapp<br>GmbH | <b>DATASHEET</b>       |  <b>LAPP GROUP</b> |
|                   | <b>SKINDICHT® CN-M</b> | <b>52032600</b><br><b>14.11.2013</b>                                                                 |

#### Technical Data

|                             |                                                                                                            |
|-----------------------------|------------------------------------------------------------------------------------------------------------|
| Article designation / size: | 12 x 1,5/3                                                                                                 |
| Clamping range ØF (mm):     | 6,5 - 8                                                                                                    |
| SW (mm):                    | 17                                                                                                         |
| Overall length, C (mm):     | 27                                                                                                         |
| Thread length, D (mm):      | 10                                                                                                         |
| Pieces / PU:                | 5                                                                                                          |
| Caution:                    | The installation dimensions<br>can be found in appendix T21                                                |
| Material:                   | Body: chrome-nickel steel in accordance with DIN, material no.<br>1.4305<br>Inner seal: FPM<br>O-ring: FPM |
| Protection rating:          | IP 68 - 5 bar                                                                                              |
| Temperature range:          | -25°C to +200°C                                                                                            |

|                    |                           |       |
|--------------------|---------------------------|-------|
| Product Management | Document: SKINDICHT® CN-M | 2 / 3 |
|--------------------|---------------------------|-------|

|                   |                        |                                                                                                      |
|-------------------|------------------------|------------------------------------------------------------------------------------------------------|
| U.I. Lapp<br>GmbH | <b>DATASHEET</b>       |  <b>LAPP GROUP</b> |
|                   | <b>SKINDICHT® CN-M</b> | <b>52032600</b><br><b>14.11.2013</b>                                                                 |

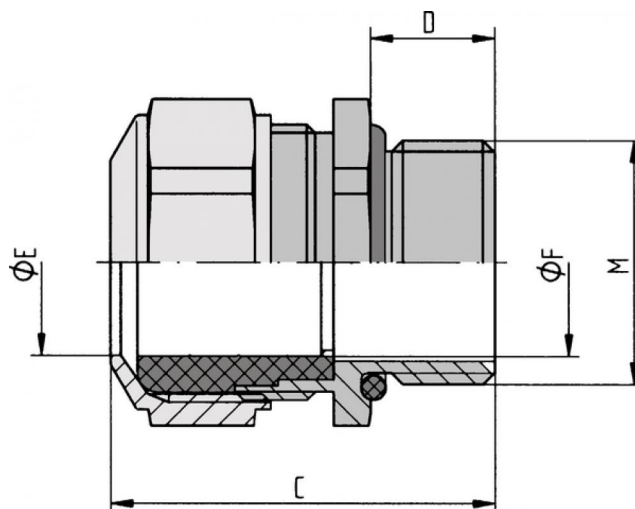

|                    |                           |       |
|--------------------|---------------------------|-------|
| Product Management | Document: SKINDICHT® CN-M | 3 / 3 |
|--------------------|---------------------------|-------|