

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® GMK	52000180 14.11.2013

Supporting surface for spanner means scratches on the housing are avoided



Application range

For locking SKINDICHT® cable glands in boreholes without thread.

Design

PG connection thread

Note

SKINTOP® GMP-GL counter nuts are recommended if there are high mechanical stress and high torques for tightening are required

Remark


Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

Article designation / size:	GMK 36
B in mm:	8
SW (mm):	60
Pieces / PU:	25
Colour delivered:	Light grey (RAL 7035)
Material:	Polystyrene
Temperature range:	-20°C to +70°C

Product Management	Document: SKINDICHT® GMK	1 / 2
--------------------	--------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® GMK	52000180 14.11.2013

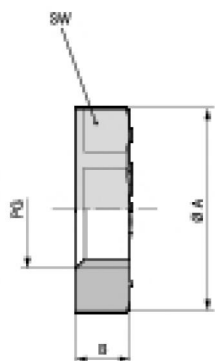

Product Management	Document: SKINDICHT® GMK	2 / 2
--------------------	--------------------------	-------