 


U.I. Lapp GmbH	DATASHEET	
	SKINDICHT® SH	52000920 14.11.2013

Seawater-resistant
Anti-magnetic
Corrosion-resistant
Stable and safe strain relief



Corrosion-resistant



Optimum strain relief



Robust



Application range

Extremely robust and solid strain relief cable gland.
Building sites
Plant engineering
Electric motor manufacturing

Design

PG connection thread

Note

Counter nut to be used: SKINDICHT® SM

Remark


Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

Article designation / size:	SH 48
Clamping range ØF (mm):	39 - 50
SW (mm):	64
Max. fitting size for installation (mm):	86
Overall length, C (mm):	39,5
Thread length, D (mm):	11.5
Pieces / PU:	5
Caution:	The installation dimensions can be found in appendix T21
On request:	Available with long connection thread
Material:	Body: nickel-plated brass
Protection rating:	IP 20

Product Management	Document: SKINDICHT® SH	1 / 2
--------------------	-------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SH	52000920 14.11.2013

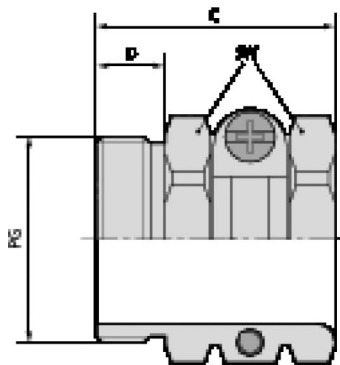

Product Management	Document: SKINDICHT® SH	2 / 2
--------------------	-------------------------	-------