 


U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SHV-M	52105420 14.11.2013

Watertight
Gentle cable clamping
Robust
High strain relief



Optimum strain relief



Robust



Waterproof



Application range

Watertight cable gland with conical sealing element.
Pumps
Floater switches

Design

Metric connection thread acc. to EN 50262

Note

Counter nut to be used: SKINDICHT® SM-M
Suitable accessory: SKINDICHT® SHV sealing cones
Example description: SHV-M 20/11/720 = metric connection thread11 = PG function thread7 = clear opening of sealing cone

Remark


Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

Article designation / size:	32 x 1,5
Clamping range ØF (mm):	23 - 25,8
Function thread PG:	29
SW1/SW2 mm:	40 / 40
Overall length, C (mm):	42,5
Thread length, D (mm):	8
Clear opening seal:	26
Pieces / PU:	10
Caution:	The installation dimensions can be found in appendix T21
Material:	Body: nickel-plated brass Sealing cone: CR O-ring: NBR
Protection rating:	IP 68 - 10 bar
Temperature range:	-20°C to +80°C

Product Management	Document: SKINDICHT® SHV-M	1 / 2
--------------------	----------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SHV-M	52105420 14.11.2013

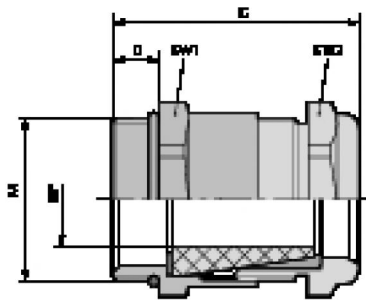

Product Management	Document: SKINDICHT® SHV-M	2 / 2
--------------------	----------------------------	-------