 


U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SHZ	52000940 14.11.2013

With incised sealing ring for adjustment to several cable diameters
High strain relief
Robust
For cables with large outer diameters



Optimum strain relief



Robust

Application range

Compact brass cable gland for reliable strain relief, solid, for large cable diameters.

Design

PG connection thread

Note

SKINDICHT® SHZ-XL is similar to the SKINDICHT® SHZ, but has an extended connection thread for thick walls
Refer to SKINDICHT® EV for additional accessories
Counter nut to be used: SKINDICHT® SM

Remark

Photographs are not to scale and do not represent detailed images of the respective products.


Technical Data

Article designation / size:	SHZ 13,5
Clamping range ØF (mm):	12,5 - 14
Max. fitting size for installation (mm):	32
SW1/SW2 mm:	22 / 22
Overall length, C (mm):	40
Thread length, D (mm):	6.5
Pieces / PU:	25
Caution:	The installation dimensions can be found in appendix T21
Material:	Body: nickel-plated brass Sealing: CR O-ring: NBR
Protection rating:	IP 55
Temperature range:	-20°C to +80°C



Product Management	Document: SKINDICHT® SHZ	1 / 2
--------------------	--------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SHZ	52000940 14.11.2013

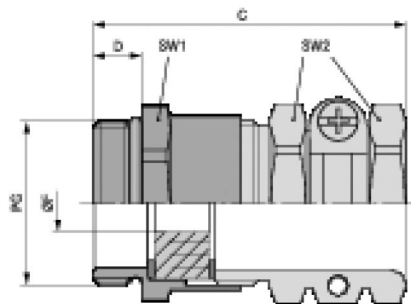

Product Management	Document: SKINDICHT® SHZ	2 / 2
--------------------	--------------------------	-------