

U.I. Lapp GmbH	<b>DATASHEET</b>	
	<b>SKINDICHT® SHZ</b>	52000960 14.11.2013

With incised sealing ring for adjustment to several cable diameters  
 High strain relief  
 Robust  
 For cables with large outer diameters



Optimum strain relief



Robust

### Application range

Compact brass cable gland for reliable strain relief, solid, for large cable diameters.

### Design

PG connection thread

### Note

SKINDICHT® SHZ-XL is similar to the SKINDICHT® SHZ, but has an extended connection thread for thick walls  
 Refer to SKINDICHT® EV for additional accessories  
 Counter nut to be used: SKINDICHT® SM

### Remark

Photographs are not to scale and do not represent detailed images of the respective products.


### Technical Data

Article designation / size:	SHZ 21
Clamping range ØF (mm):	15,5 - 21
Max. fitting size for installation (mm):	46
SW1/SW2 mm:	30 / 30
Overall length, C (mm):	47
Thread length, D (mm):	7
Pieces / PU:	25
Caution:	The installation dimensions can be found in appendix T21
Material:	Body: nickel-plated brass Sealing: CR O-ring: NBR
Protection rating:	IP 55
Temperature range:	-20°C to +80°C



Product Management	Document: SKINDICHT® SHZ	1 / 2
--------------------	--------------------------	-------

U.I. Lapp GmbH	<h1>DATASHEET</h1>	
	<h2>SKINDICHT® SHZ</h2>	<b>52000960</b> <b>14.11.2013</b>

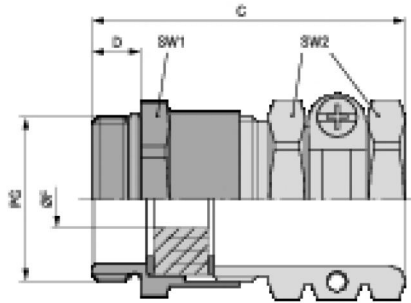

Product Management	Document: SKINDICHT® SHZ	2 / 2
--------------------	--------------------------	-------