 


U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SHZ-M	52106730 14.11.2013

With incised sealing ring for adjustment to several cable diameters
High strain relief
Robust
For cables with large outer diameters



Mechanical resistance



Optimum strain relief

Application range

Compact brass cable gland for reliable strain relief, solid, for large cable diameters.

Design

Metric connection thread acc. to EN 50262

Note

SKINDICHT® SHZ-M-XL is similar to the SKINDICHT® SHZ-M, but has an extended connection thread for thick walls

Counter nut to be used: SKINDICHT® SM-M

Example description: SHZ-M 16/916 = metric connection thread 9 = PG function thread

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

Article designation / size: 20 x 1,5

Ø-F mm: 8,5 - 13

Max. fitting size for installation (mm): 32

Function thread PG: 13.5

SW1/SW2 mm: 22 / 22

Overall length, C (mm): 39,5

Thread length, D (mm): 6

Pieces / PU: 25

Caution: The installation dimensions
can be found in appendix T21

Material: Body: nickel-plated brass
Sealing ring: CR/NBR
O-ring: NBR


Protection rating: IP 55

Temperature range: -20°C to +80°C



Product Management	Document: SKINDICHT® SHZ-M	1 / 2
--------------------	----------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SHZ-M	52106730 14.11.2013

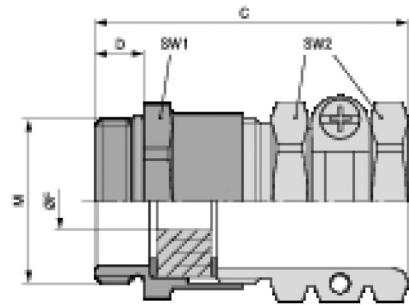

Product Management	Document: SKINDICHT® SHZ-M	2 / 2
--------------------	----------------------------	-------