 


U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SK	52004250 14.11.2013

Reliable strain relief
Wide clamping range



Wide clamping range



Optimum strain relief



Robust

Application range

Cable gland with two solid brass saddle clamps
connectors
Switches
Control panels

Design

PG connection thread

Note

Counter nut to be used: SKINDICHT® SM

Remark

Photographs are not to scale and do not represent detailed images of the respective products.


Technical Data

Article designation / size:	SK 13,5
Clamping range ØF (mm):	12 - 16,5
SW (mm):	22
Max. fitting size for installation (mm):	30
Overall length, C (mm):	18,5
Thread length, D (mm):	7.5
Pieces / PU:	25
Caution:	The installation dimensions can be found in appendix T21
On request:	Available with long connection thread
Material:	Body: nickel-plated brass
Protection rating:	IP 20



Product Management	Document: SKINDICHT® SK	1 / 2
--------------------	-------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SK	52004250 14.11.2013

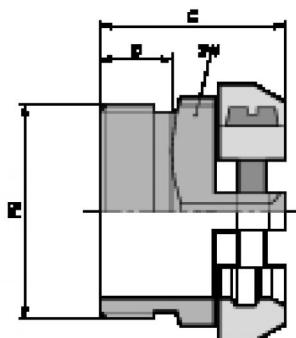

Product Management	Document: SKINDICHT® SK	2 / 2
--------------------	-------------------------	-------