 


U.I. Lapp GmbH	<b>DATASHEET</b>	
	<b>SKINDICHT® SK</b>	51712740 14.11.2013

Reliable strain relief  
Wide clamping range



Wide clamping range



Optimum strain relief



Robust



### Application range

Cable gland with two solid brass saddle clamps  
connectors  
Switches  
Control panels

### Design

PG connection thread

### Note

Counter nut to be used: SKINDICHT® SM

### Remark


Photographs are not to scale and do not represent detailed images of the respective products.

### Technical Data

Article designation / size:	SK 29
Clamping range ØF (mm):	20 - 31
SW (mm):	41
Max. fitting size for installation (mm):	58
Overall length, C (mm):	26
Thread length, D (mm):	8
Pieces / PU:	10
Caution:	The installation dimensions can be found in appendix T21
On request:	Available with long connection thread
Material:	Body: nickel-plated brass
Protection rating:	IP 20

Product Management	Document: SKINDICHT® SK	1 / 2
--------------------	-------------------------	-------

U.I. Lapp GmbH	<h1>DATASHEET</h1>	 <b>LAPP GROUP</b>
	<b>SKINDICHT® SK</b>	<b>51712740</b> <b>14.11.2013</b>

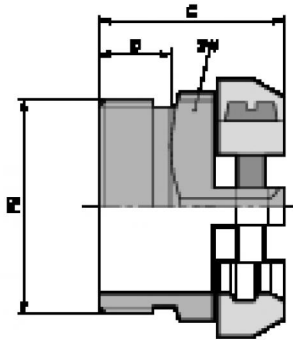

Product Management	Document: SKINDICHT® SK	2 / 2
--------------------	-------------------------	-------