
 


|                   |                      |                                                                                                      |
|-------------------|----------------------|------------------------------------------------------------------------------------------------------|
| U.I. Lapp<br>GmbH | <b>DATASHEET</b>     |  <b>LAPP GROUP</b> |
|                   | <b>SKINDICHT® SR</b> | <b>52001170</b><br><b>14.11.2013</b>                                                                 |

Reliable bending and anti-kink protection  
High strain relief  
Robust  
For cables with large outer diameters  
High degree of protection

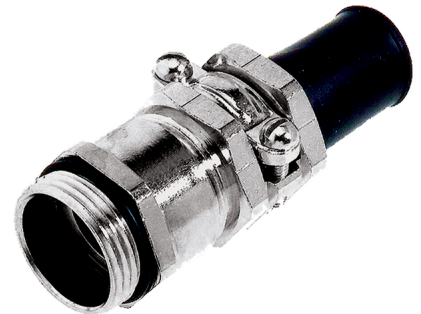

Wide clamping range



Optimum strain relief



Robust

### Application range

Cables for electrical appliances and machinery that are moved under normal use must be protected against excessive bending as required in accordance with VDE 0700-1

Handheld device  
Portable equipment  
Building sites  
Moving machine parts

### Design

PG connection thread

### Note

Counter nut to be used: SKINDICHT® SM  
For EMC version, refer to SKINDICHT® SRE

### Remark

Photographs are not to scale and do not represent detailed images of the respective products.

|                    |                         |       |
|--------------------|-------------------------|-------|
| Product Management | Document: SKINDICHT® SR | 1 / 3 |
|--------------------|-------------------------|-------|


|                   |                      |                                                                                                      |
|-------------------|----------------------|------------------------------------------------------------------------------------------------------|
| U.I. Lapp<br>GmbH | <b>DATASHEET</b>     |  <b>LAPP GROUP</b> |
|                   | <b>SKINDICHT® SR</b> | <b>52001170</b><br><b>14.11.2013</b>                                                                 |

#### Technical Data

|                                          |                                                                      |
|------------------------------------------|----------------------------------------------------------------------|
| Article designation / size:              | SR 36/33                                                             |
| Clamping range ØF (mm):                  | 30 - 33                                                              |
| Max. fitting size for installation (mm): | 70                                                                   |
| SW1/SW2 mm:                              | 50 / 50                                                              |
| Overall length, C (mm):                  | 110                                                                  |
| Thread length, D (mm):                   | 9                                                                    |
| Pieces / PU:                             | 5                                                                    |
| Caution:                                 | The installation dimensions<br>can be found in appendix T21          |
| On request:                              | Available with long connection thread                                |
| Material:                                | Body: nickel-plated brass<br>O-ring: NBR<br>Anti-kink protection: CR |
| Protection rating:                       | IP 65                                                                |
| Temperature range:                       | -20°C to +80°C                                                       |

|                    |                         |       |
|--------------------|-------------------------|-------|
| Product Management | Document: SKINDICHT® SR | 2 / 3 |
|--------------------|-------------------------|-------|

|                   |                      |                                                                                                      |
|-------------------|----------------------|------------------------------------------------------------------------------------------------------|
| U.I. Lapp<br>GmbH | <b>DATASHEET</b>     |  <b>LAPP GROUP</b> |
|                   | <b>SKINDICHT® SR</b> | <b>52001170</b><br><b>14.11.2013</b>                                                                 |

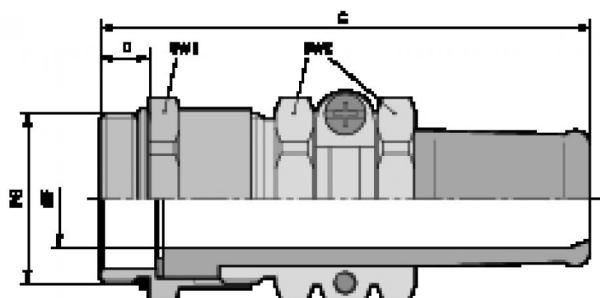

|                    |                         |       |
|--------------------|-------------------------|-------|
| Product Management | Document: SKINDICHT® SR | 3 / 3 |
|--------------------|-------------------------|-------|