

|                   |                        |                                                                                    |
|-------------------|------------------------|------------------------------------------------------------------------------------|
| U.I. Lapp<br>GmbH | <b>DATASHEET</b>       |  |
|                   | <b>SKINDICHT® SVFK</b> | <b>52005680</b><br><b>14.11.2013</b>                                               |

Economical type  
 Lateral sealing lips fit automatically around various cable dimensions  
 Cable-specific seal dimensions are no longer necessary  
 Tolerance  
 Large opening allows clamping of up to two flat cables



### Application range

For inserting flat cables.  
 Conveyor systems  
 Pumps  
 Lifts  
 Control cabinet manufacturing

### Design

PG connection thread

### Note

Counter nut to be used: SKINDICHT® GMK  
 For suitable flat cables, refer to ÖLFLEX® LIFT F for indoor applications or ÖLFLEX® CRANE F for outdoor applications

### Remark


Photographs are not to scale and do not represent detailed images of the respective products.

### Technical Data

|                                 |                                                             |
|---------------------------------|-------------------------------------------------------------|
| Article designation / size:     | SVFK 21                                                     |
| Min./max. flat cable width:     | 10 - 20,5                                                   |
| Min./max. cable thickness (mm): | 3 - 8                                                       |
| SW1/SW2 mm:                     | 32 / 30                                                     |
| Overall length, C (mm):         | 43                                                          |
| Thread length, D (mm):          | 11                                                          |
| Pieces / PU:                    | 25                                                          |
| Caution:                        | The installation dimensions<br>can be found in appendix T21 |
| Colour delivered:               | Light grey (RAL 7035)                                       |
| Material:                       | Body: Polystyrene<br>Special sealing insert: CR             |
| Protection rating:              | IP 54                                                       |
| Temperature range:              | -20°C to +60°C                                              |

|                    |                           |       |
|--------------------|---------------------------|-------|
| Product Management | Document: SKINDICHT® SVFK | 1 / 2 |
|--------------------|---------------------------|-------|

|                   |                        |                                                                                                      |
|-------------------|------------------------|------------------------------------------------------------------------------------------------------|
| U.I. Lapp<br>GmbH | <b>DATASHEET</b>       |  <b>LAPP GROUP</b> |
|                   | <b>SKINDICHT® SVFK</b> | <b>52005680</b><br><b>14.11.2013</b>                                                                 |

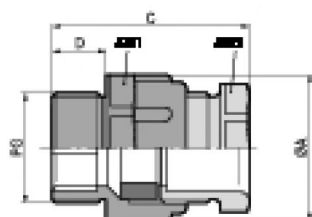

|                    |                           |       |
|--------------------|---------------------------|-------|
| Product Management | Document: SKINDICHT® SVFK | 2 / 2 |
|--------------------|---------------------------|-------|