

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SVFK-M	52107903 14.11.2013

Economical type
 Lateral sealing lips fit automatically around various cable dimensions
 Cable-specific seal dimensions are no longer necessary
 Tolerance
 Large opening allows clamping of up to two flat cables



Wide clamping range



Maximum vibration protection



Assembly time



Application range

For inserting flat cables.
 Conveyor systems
 Pumps
 Lifts
 Control cabinet manufacturing

Design

Metric connection thread acc. to EN 50262

Note

Counter nut to be used: SKINTOP® GMP-GL-M
 For suitable flat cables, refer to ÖLFLEX® LIFT F for indoor applications or ÖLFLEX® CRANE F for outdoor applications

Remark


Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

Article designation / size:	SVFK-M 50 x 1,5
Min./max. flat cable width:	26 / 35
Min./max. cable thickness (mm):	4 - 11,5
SW1/SW2 mm:	53 / 50
Overall length, C (mm):	50,5
Thread length, D (mm):	11
Pieces / PU:	5
Caution:	The installation dimensions can be found in appendix T21
Colour delivered:	Light grey (RAL 7035)
Material:	Body: Polyamide Special sealing insert: CR
Temperature range:	-30°C to +80°C

Product Management	Document: SKINDICHT® SVFK-M	1 / 2
--------------------	-----------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SVFK-M	52107903 14.11.2013

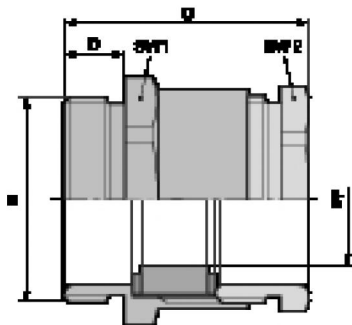

Product Management	Document: SKINDICHT® SVFK-M	2 / 2
--------------------	-----------------------------	-------