

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SVRE-M	52105006 14.11.2013

With incised sealing ring for adjustment to several cable diameters
Fewer sizes need to be kept in stock



Robust



Reliability



Application range

Brass cable gland with hexagonal fitting and variable incised sealing ring.

Design

Metric connection thread acc. to EN 50262

Note

Refer to SKINDICHT® EV for additional accessories
Counter nut to be used: SKINDICHT® SM-M

Remark


Viton® is a registered trademark of DuPont de Nemours
Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

Article designation / size:	63 x 1,5
Incised sealing ring ØF (mm):	40.5/44/47/50.5
Max. internal Ø (mm):	54
Function thread PG:	48
SW1/SW2 mm:	66 / 60
Overall length, C (mm):	45,1
Thread length, D (mm):	10
Pieces / PU:	5
Caution:	The installation dimensions can be found in appendix T21
On request:	Available with long connection thread Available with VITON® incised ring
Material:	Body: nickel-plated brass Incised seal: CR/NBR
Protection rating:	IP 54
Temperature range:	-20°C to +80°C

Product Management	Document: SKINDICHT® SVRE-M	1 / 2
--------------------	-----------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SVRE-M	52105006 14.11.2013

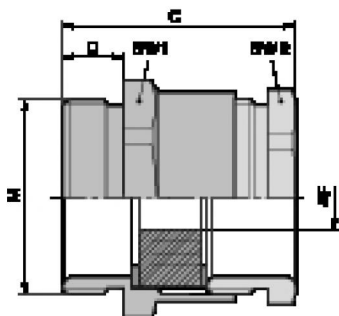

Product Management	Document: SKINDICHT® SVRE-M	2 / 2
--------------------	-----------------------------	-------