

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SVRN	52000241 14.11.2013

High mechanical stability
Optimum strain relief



Robust

Application range

Brass cable gland with hexagonal fitting, for fast assembly with a flat spanner.

Design

PG connection thread

Note

Counter nut to be used: SKINDICHT® SM

Remark

Photographs are not to scale and do not represent detailed images of the respective products.


Technical Data

Article designation / size:	SVRN 13012/N
PG size:	13.5
Clamping range (mm):	12
SW1/SW2 mm:	22 / 20
Overall length, C (mm):	26,1
Thread length, D (mm):	6.5
Pieces / PU:	50
Caution:	The installation dimensions can be found in appendix T21
Material:	Body: nickel-plated brass Sealing ring: CR
Protection rating:	IP 54
Temperature range:	-20°C to +100°C



Product Management	Document: SKINDICHT® SVRN	1 / 2
--------------------	---------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINDICHT® SVRN	52000241 14.11.2013

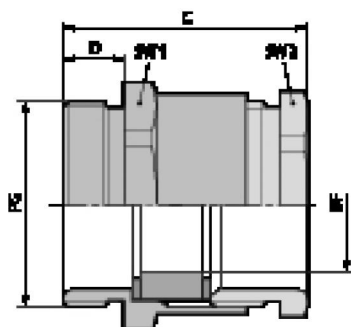

Product Management	Document: SKINDICHT® SVRN	2 / 2
--------------------	---------------------------	-------