

U.I. Lapp GmbH	<b>DATASHEET</b>	
	<b>SKINDICHT® SVRN</b>	52000260 14.11.2013

High mechanical stability  
Optimum strain relief



Robust

### Application range

Brass cable gland with hexagonal fitting, for fast assembly with a flat spanner.

### Design

PG connection thread

### Note

Counter nut to be used: SKINDICHT® SM

### Remark

Photographs are not to scale and do not represent detailed images of the respective products.


### Technical Data

Article designation / size:	SVRN 21018/N
PG size:	21
Clamping range (mm):	18
SW1/SW2 mm:	30 / 28
Overall length, C (mm):	29,6
Thread length, D (mm):	7
Pieces / PU:	50
Caution:	The installation dimensions can be found in appendix T21
Material:	Body: nickel-plated brass Sealing ring: CR
Protection rating:	IP 54
Temperature range:	-20°C to +100°C



Product Management	Document: SKINDICHT® SVRN	1 / 2
--------------------	---------------------------	-------

U.I. Lapp GmbH	<b>DATASHEET</b>	 <b>LAPP GROUP</b>
	<b>SKINDICHT® SVRN</b>	<b>52000260</b> <b>14.11.2013</b>

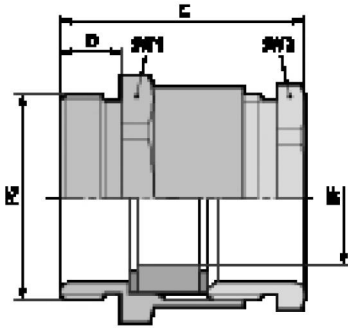

Product Management	Document: SKINDICHT® SVRN	2 / 2
--------------------	---------------------------	-------