


U.I. Lapp GmbH	DATASHEET	
	SKINTOP® BT	53015420 14.11.2013

Reliable bending and anti-kink protection
Cable conservation
Functional reliability

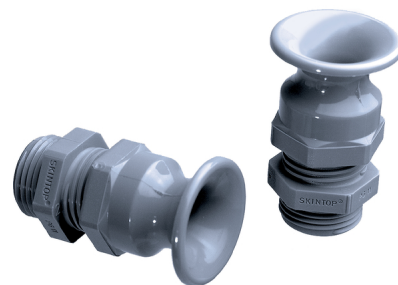

 
Good chemical resistance



Wide clamping range



Mechanical resistance



Optimum strain relief



Temperature-resistant



Variety of approval certifications

Application range

Cables for electrical appliances and machinery that are moved under normal use must be protected against excessive bending as required in accordance with VDE 0700-1

Handheld device

Apparatus construction

Light and sound applications

Moving machine parts

Design

PG connection thread

Norm references / Approvals

UL File Nr. E79903

Note

Refer to SKINTOP® PG accessories for suitable accessories

Counter nut to be used: SKINTOP® GMP-GL

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Product Management	Document: SKINTOP® BT	1 / 3
--------------------	-----------------------	-------


U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® BT	53015420 14.11.2013

Technical Data

Article designation / size:	11
Clamping range ØF (mm):	4 - 10
SW (mm):	22
Overall length, C (mm):	47,7
Thread length, D (mm):	8
Pieces / PU:	100
Caution:	Refer to Appendix T21 for the installation dimensions and torques
Colour delivered:	Silver grey (RAL 7001)
Material:	Body: Polyamide Seal: CR
Protection rating:	IP 68 - 5 bar
Temperature range:	-20°C to +80°C

Product Management	Document: SKINTOP® BT	2 / 3
--------------------	-----------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® BT	53015420 14.11.2013

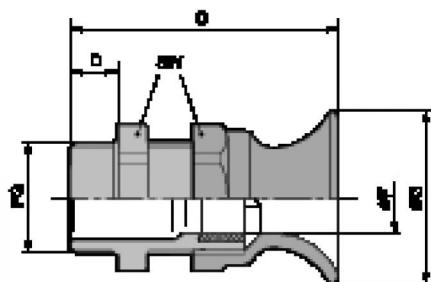

Product Management	Document: SKINTOP® BT	3 / 3
--------------------	-----------------------	-------