

|                   |                     |                                                                                                      |
|-------------------|---------------------|------------------------------------------------------------------------------------------------------|
| U.I. Lapp<br>GmbH | <b>DATASHEET</b>    |  <b>LAPP GROUP</b> |
|                   | <b>SKINTOP® MSR</b> | <b>52015790</b><br><b>14.11.2013</b>                                                                 |

For the benefits, refer to SKINTOP® MS



 
Good chemical resistance



Corrosion-resistant



Mechanical resistance



Optimum strain relief



Robust



Temperature-resistant



Variety of approval certifications



### Application range

With reducing seal insert, to seal cables with smaller outer diameters.

### Design

PG connection thread

### Note

Refer to SKINTOP® PG accessories for suitable accessories

Counter nut to be used: SKINDICHT® SM

### Remark

Photographs are not to scale and do not represent detailed images of the respective products.

|                    |                        |       |
|--------------------|------------------------|-------|
| Product Management | Document: SKINTOP® MSR | 1 / 3 |
|--------------------|------------------------|-------|


|                   |                     |                                                                                                      |
|-------------------|---------------------|------------------------------------------------------------------------------------------------------|
| U.I. Lapp<br>GmbH | <b>DATASHEET</b>    |  <b>LAPP GROUP</b> |
|                   | <b>SKINTOP® MSR</b> | <b>52015790</b><br><b>14.11.2013</b>                                                                 |

#### Technical Data

|                             |                                                                                   |
|-----------------------------|-----------------------------------------------------------------------------------|
| Article designation / size: | MSR 11                                                                            |
| Clamping range ØF (mm):     | 3 - 7                                                                             |
| SW (mm):                    | 20                                                                                |
| Overall length, C (mm):     | 32                                                                                |
| Thread length, D (mm):      | 6                                                                                 |
| Pieces / PU:                | 50                                                                                |
| Caution:                    | Refer to Appendix T21 for the installation dimensions and torques                 |
| Material:                   | Body: nickel-plated brass<br>Insert: polyamide<br>Sealing ring: CR<br>O-ring: NBR |
| Protection rating:          | IP 68 - 5 bar                                                                     |
| Temperature range:          | -30°C to +100°C                                                                   |

|                    |                        |       |
|--------------------|------------------------|-------|
| Product Management | Document: SKINTOP® MSR | 2 / 3 |
|--------------------|------------------------|-------|

|                   |                     |                                                                                                      |
|-------------------|---------------------|------------------------------------------------------------------------------------------------------|
| U.I. Lapp<br>GmbH | <b>DATASHEET</b>    |  <b>LAPP GROUP</b> |
|                   | <b>SKINTOP® MSR</b> | <b>52015790</b><br><b>14.11.2013</b>                                                                 |

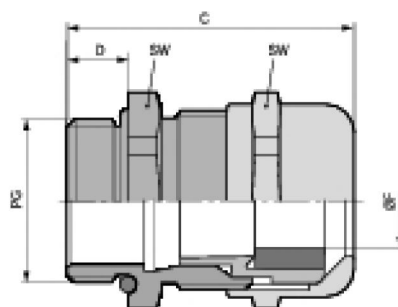

|                    |                        |       |
|--------------------|------------------------|-------|
| Product Management | Document: SKINTOP® MSR | 3 / 3 |
|--------------------|------------------------|-------|