

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® MSR	52015800 14.11.2013

For the benefits, refer to SKINTOP® MS



 
Good chemical resistance



Corrosion-resistant



Mechanical resistance



Optimum strain relief



Robust



Temperature-resistant



Variety of approval certifications



Application range

With reducing seal insert, to seal cables with smaller outer diameters.

Design

PG connection thread

Note

Refer to SKINTOP® PG accessories for suitable accessories

Counter nut to be used: SKINDICHT® SM

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Product Management	Document: SKINTOP® MSR	1 / 3
--------------------	------------------------	-------


U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® MSR	52015800 14.11.2013

Technical Data

Article designation / size:	MSR 13,5
Clamping range ØF (mm):	4 - 9
SW (mm):	22
Overall length, C (mm):	34
Thread length, D (mm):	6.5
Pieces / PU:	50
Caution:	Refer to Appendix T21 for the installation dimensions and torques
Material:	Body: nickel-plated brass Insert: polyamide Sealing ring: CR O-ring: NBR
Protection rating:	IP 68 - 5 bar
Temperature range:	-30°C to +100°C

Product Management	Document: SKINTOP® MSR	2 / 3
--------------------	------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® MSR	52015800 14.11.2013

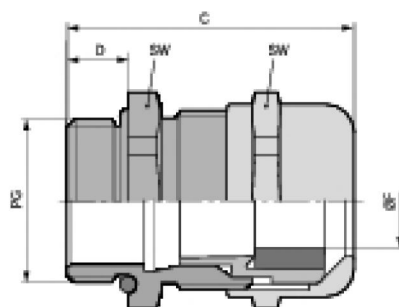

Product Management	Document: SKINTOP® MSR	3 / 3
--------------------	------------------------	-------