

U.I. Lapp GmbH	<b>DATASHEET</b>	
	<b>SKINTOP® MSR</b>	52015810 14.11.2013

For the benefits, refer to SKINTOP® MS



Good chemical resistance



Corrosion-resistant



Mechanical resistance



Optimum strain relief



Robust



Temperature-resistant



Variety of approval certifications



### Application range

With reducing seal insert, to seal cables with smaller outer diameters.

### Design

PG connection thread

### Note

Refer to SKINTOP® PG accessories for suitable accessories  
Counter nut to be used: SKINDICHT® SM

### Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Product Management	Document: SKINTOP® MSR	1 / 3
--------------------	------------------------	-------


U.I. Lapp GmbH	<h1>DATASHEET</h1>	 <b>LAPP GROUP</b>
	<b>SKINTOP® MSR</b>	52015810 14.11.2013

**Technical Data**

Article designation / size:	MSR 16
Clamping range ØF (mm):	6 - 13
SW (mm):	24
Overall length, C (mm):	35
Thread length, D (mm):	6.5
Pieces / PU:	50
Caution:	Refer to Appendix T21 for the installation dimensions and torques
Material:	Body: nickel-plated brass Insert: polyamide Sealing ring: CR O-ring: NBR
Protection rating:	IP 68 - 5 bar
Temperature range:	-30°C to +100°C

Product Management	Document: SKINTOP® MSR	2 / 3
--------------------	------------------------	-------

U.I. Lapp GmbH	<b>DATASHEET</b>	 <b>LAPP GROUP</b>
	<b>SKINTOP® MSR</b>	52015810 14.11.2013

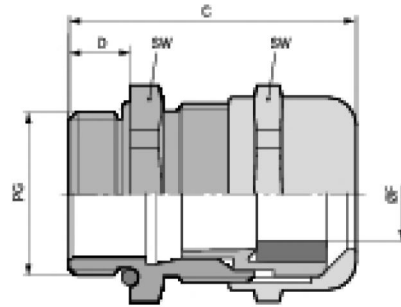

Product Management	Document: SKINTOP® MSR	3 / 3
--------------------	------------------------	-------