

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® MSR-XL	52115830 14.11.2013

 
For the benefits, refer to SKINTOP® MS-XL



Good chemical resistance



Mechanical resistance



Optimum strain relief



Robust



Temperature-resistant



Variety of approval certifications



Application range

With reducing seal insert, to seal cables with smaller outer diameters.

Design

PG connection thread

Note

Refer to SKINTOP® PG accessories for suitable accessories

Counter nut to be used: SKINDICHT® SM

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Product Management	Document: SKINTOP® MSR-XL	1 / 3
--------------------	---------------------------	-------


U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® MSR-XL	52115830 14.11.2013

Technical Data

Article designation / size:	MSR 29
Clamping range ØF (mm):	10,5 - 20
SW (mm):	40
Overall length, C (mm):	52
Thread length, D (mm):	15
Pieces / PU:	25
Caution:	Refer to Appendix T21 for the installation dimensions and torques
Material:	Body: nickel-plated brass Insert: polyamide Sealing ring: CR O-ring: NBR
Protection rating:	IP 68 - 5 bar
Temperature range:	-30°C to +100°C

Product Management	Document: SKINTOP® MSR-XL	2 / 3
--------------------	---------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® MSR-XL	52115830 14.11.2013

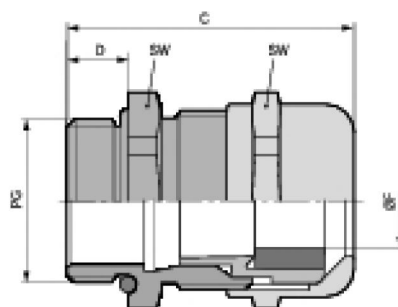

Product Management	Document: SKINTOP® MSR-XL	3 / 3
--------------------	---------------------------	-------